

12322 Tungsten carbide scribing iron

- straight type
- sturdy shank with tungsten carbide tip
- can be reground
- holder and clip



Code	L mm	g	
77 10 0001	150	40	10

12374 Wire brush

- wood, steel wire dia. 0.35 mm



Code	L mm	Rows	g	
77 09 0000	290	4	129	10

12377 Wire brush

- with brass coated steel bristles



Code	L mm	g	
77 09 00 10	270	140	24

12378 File brush



Code	L mm	g	
77 25 0000	260	74	5

13115 Brass wire brush

- for use on light alloys



Code	L mm	Rows	g	
77 47 0001	280	4	134	1


12481 Scraper



Code	L mm	b mm	g	
77 07 0000	212	60	65	10

12600 Magnetic lifters

- loss of adhesion above 80° C

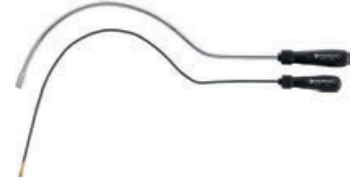

Code	lifting power g	Ø mm	L mm	g	
77 26 00 27	270 ¹⁾	5	500	30	1
77 26 00 25	500	8	460	70	1
77 26 00 60	1800	15	525	230	1
77 26 02 00	3000	19	535	297	1

¹⁾ miniature magnetic lifter with tiny head, very powerful

12910 Adjustable hook spanners

- for slotted nuts as per DIN 1810
- adjustable



Code	size	Ø mm	g	
44 01 00 01	1	20-42	90	5
44 01 00 02	2	45-90	245	5
44 01 00 03	3	95-165	686	5

12920N Telescopic mirror

- with non-twisting, oval-section telescopic rod



Code	dimensions mirrors mm	L mm	g	
77 40 10 01	65 x 43	310-750	65	1

12920NR-1 Replacement mirror for No 12920N

Code	g	
79 40 10 01	39	1

12920NR-2 Stainless steel replacement mirror for No 12920N

Code	g	
79 40 10 02	43	1

12921M Telescopic stainless steel mirror

- unbreakable mirrors made of stainless steel (prevents FOD)
- no bolted joints (prevents FOD)
- rust-proof stainless steel telescopic arm
- universal joint (180° action), self-tensioning
- special plastic handle ensures a firm grip and safe working, resistant to chemicals



Code	size	mm	L mm	g	
77 40 10 32	1 1/4"/32 mm	Ø 32	171-699	60	1
77 40 10 45	1 3/4" x 2 3/4"/45 x 70 mm	□ 45 x 70	178-927	76	1
77 40 10 57	2 1/4"/57 mm	Ø 57	178-921	70	1