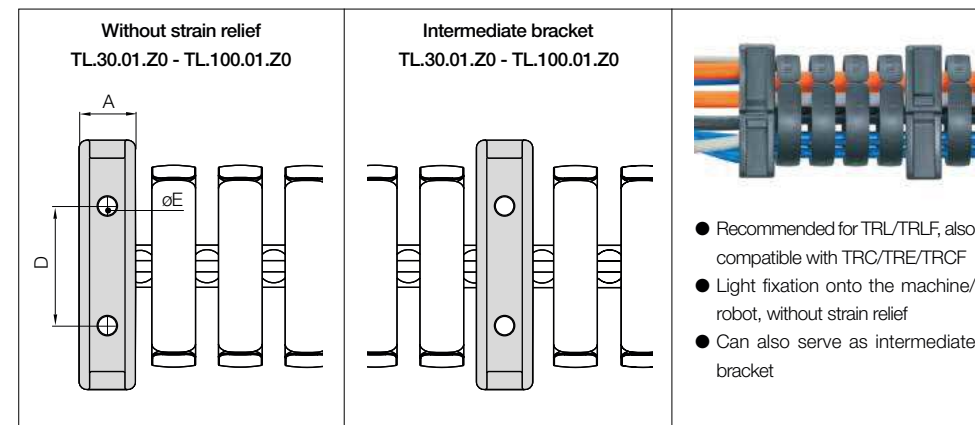
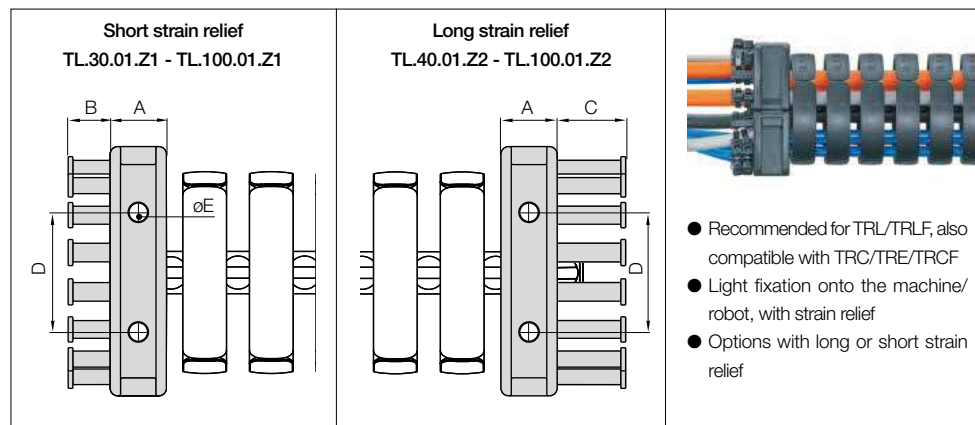


Light mounting brackets | **With strain relief**

Ø	Part No. with short strain relief	Part No. with long strain relief	A	B	C	D	E
Index			[mm]	[mm]	[mm]	[mm]	[mm]
30.	▶ TL.30.01.Z1	–	13	12.5	–	24	4.5
40.	▶ TL.40.01.Z1 ¹⁾	TL.40.01.Z2	14	12.5	20	36	5.8
50.	▶ Alternative: standard mounting bracket						
60.	▶ TL.60.01.Z1 ¹⁾	TL.60.01.Z2	20	17	27	48	5.8
65.	▶ TL.65.01.Z1 ¹⁾	–	27	13.5	–	64	6.5
70.	▶ TL.70.01.Z1 ¹⁾	TL.70.01.Z2	27	17.5	27.5	64	6.5
85.	▶ TL.85.01.Z1	–	30	26.5	–	64	6.5
85. (R 240)	▶ Alternative: standard mounting bracket						
100.	▶ TL.100.01.Z1 ¹⁾	TL.100.01.Z2	30	22.5	42.5	64	6.5
125.	▶ Alternative: standard mounting bracket						

1) For moving end (ball) suitable only for series TRL/TRLF

Light mounting brackets | **Without strain relief**

Ø	Part No. without strain relief or as intermediate bracket	A	B	C	D	E
Index		[mm]	[mm]	[mm]	[mm]	[mm]
30.	▶ TL.30.01.Z0	13	–	–	24	4.5
40.	▶ TL.40.01.Z0	14	–	–	36	5.8
50.	▶ Alternative: standard mounting bracket					
60.	▶ TL.60.01.Z0	20	–	–	48	5.8
65.	▶ TL.65.01.Z0	27	–	–	64	6.5
70.	▶ TL.70.01.Z0	27	–	–	64	6.5
85.	▶ TL.85.01.Z0	30	–	–	64	6.5
85. (R 240)	▶ Alternative: standard mounting bracket					
100.	▶ TL.100.01.Z0	30	–	–	64	6.5
125.	▶ Alternative: standard mounting bracket					

