

Solenoid valve

EMVP 10 24V-DC 3/2 NO/NC

Part no.:10.05.02.00144

<https://www.schmalz.com/10.05.02.00144>

Home > Vacuum Technology for Automation > Vacuum Components > Valve Technology > Solenoid Valves > Solenoid Valves EMVP > EMVP 10 24V-DC 3/2 NO/NC

Solenoid valve EMVP for vacuum, pneumatic pilot control



Nominal size: 10 mm

Voltage DC: 24V - DC

Function: 3/2-way valve


Control valve: Optional NO/NC

Connecting thread: G3/8"-F

Nominal flow rate: 10 m³/h

Weight: 0.42 kg

Design Data

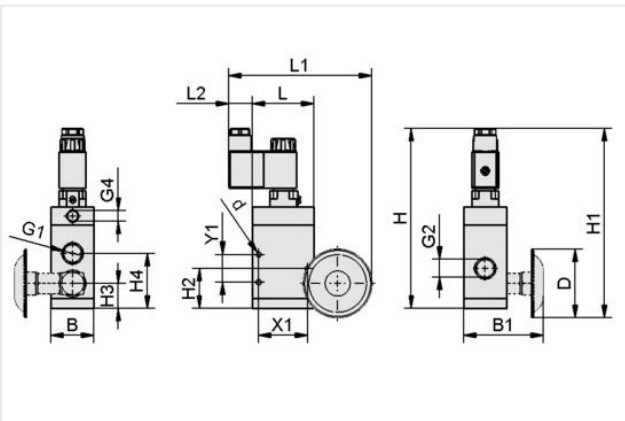

Attribute	Value
B	35 mm
B1	67 mm
d	4.30 mm
D	56 mm
G1	G3/8"-F
G2	G3/8"-F
G4	G1/8"-F
H	147 mm
H1	154.50 mm
H2	32.80 mm
H3	20.50 mm
H4	45 mm
L	50 mm
L1	117 mm
L2	19.50 mm
X1	40 mm
Y1	22.50 mm

Technical Data

Attribute	Value
-----------	-------

Contact Schmalz

Schmalz Inc. | 5850 Oak Forest Drive, Raleigh, NC 27616, United States | +1 (919) 713-0880 | schmalz.us@schmalz.com

Solenoid valve

EMVP 10 24V-DC 3/2 NO/NC

Part no.:10.05.02.00144

<https://www.schmalz.com/10.05.02.00144>

Nominal size	10 mm
Nominal flow rate	10 m³/h
Control valve	Optional NO/NC
Nominal flow rate	167 l/min
Power consumption DC	5 W
Voltage DC	24V - DC
Closing time	22 ms
Weight	0.42 kg
Product family	EMVP

Accessories



FAS 63x47 G3/8-AG EMVP-10

Part no.:10.05.01.00065

External diameter D: 63 mm

Length L: 47 mm

Thread G1: G3/8"-M

Construction use: Solenoid valve

Size: 10



STEC 4 S-M12-4 St

Part no.:10.05.02.00157

Contact Schmalz

Schmalz Inc. | 5850 Oak Forest Drive, Raleigh, NC 27616, United States | +1 (919) 713-0880 | schmalz.us@schmalz.com