


Product data						
Product code	VG03-0053		STK-code	1914358	EAN-code	6430051860324
Product name	OJL-connector 135 Blue				ETIM class	EC000276
Wires	IN 1x(Al/Cu) 2,5-35 mm²/ 1x (Al/Cu) 2,5-10 mm² OUT: 4x (Cu) 2,5-16mm²/ 2x (Cu) 2,5-10 mm²					
Technical data						
Nominal current (IEC)	Cu	135	A			
	Al	120	A			
Nominal voltage (IEC)		1000	V			
		-				
		-				
		-				
Number of poles		1	pcs			
Max. Cross section		35	mm²			
Tightening torque						
	2,5-16 mm² (M6)	3	Nm			
	25-35 mm² (M8)	6	Nm			
		-				
		-				
Input	1x Al/Cu 2,5-35 mm², 1x Al/Cu 2,5-10 mm²					
Output	4x Cu 2,5-16 mm², 2x Cu 2,5-10 mm²					
Operating temperature		80	°C			
Weight		75	g			
IP-protection		IP20				
Standards	EN 61238-1:2003; EN 60947-7-1:2009					
Color / Material	Blue Cover PC, Grey Housing RAL 7035 PA66/V0, Connector part tin plated aluminium					
Mounting / Connection	Din rail and 2x screw (M5) mounting					
Description						



The single pole distribution block for branching connection. Distribution block with 2 inputs and it will distribute the current through 6 output cables. Connector is made from tin plated aluminium and housing is PA66 V0.

Drawing

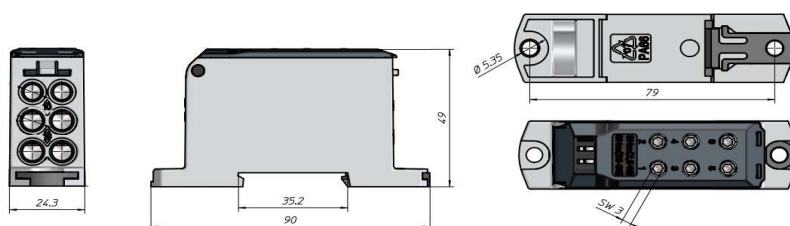

Package			
Package	Box	Pcs / Package	20
		Weight [kg]	1,50
Length [mm]	300	Width [mm]	205
		Height [mm]	100

Ouneva Oy

Teollisuustie 21
FI-82730 Tuupovaara
Finland

Tel. +358 400 179 750
info@ouneva.fi

www.ounevagroup.fi
www.ounevaproductions.fi