




USB 2.0 C Male to C Male Dual Right Angle 5A Cable

PD100W/5A

USB-C Dual Right Angle Cable

Designed for mobile gamer

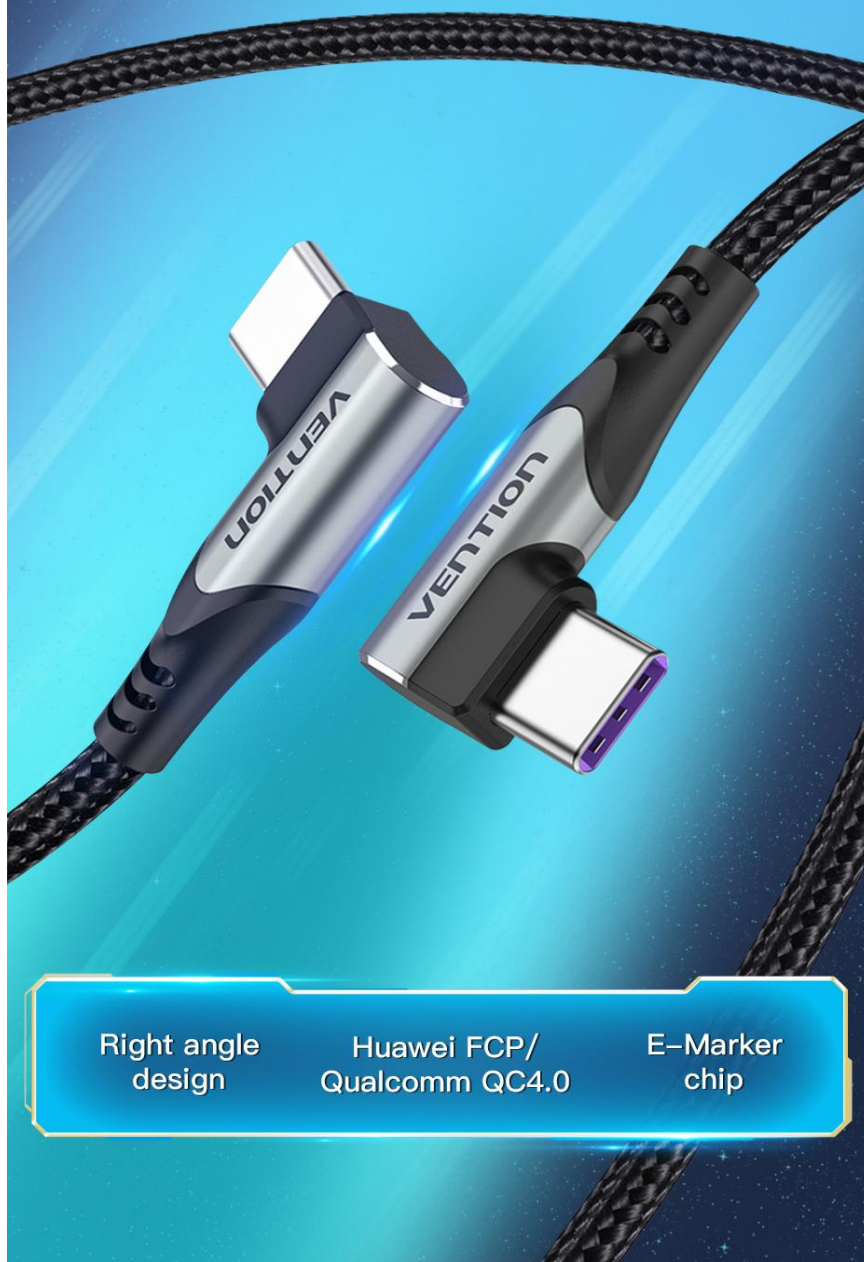

Right angle
design

Huawei FCP/
Qualcomm QC4.0

E-Marker
chip

Applicable for Narrow Space



Right angle interface

Easy for plugging




Normal interface

Cause damage
to cable joint

Right Angle Interface

Ergonomic design to fit hand

90°
interface

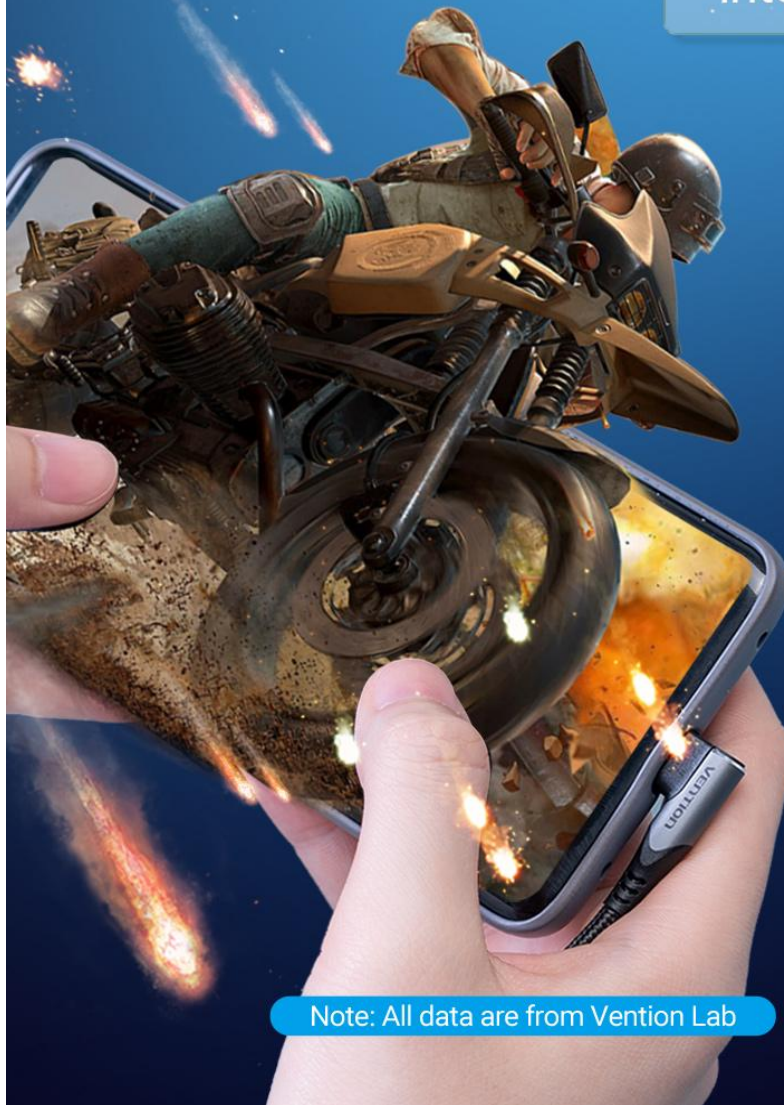

Note: All data are from Vention Lab

PD100W Fast Charge



Around **2** Hours full of:
MacBook Pro 2018

Around **2.4** Hours full of:
iPad Pro 11"

Around **2.5** Hours full of:
Nintendo Switch

Note: All data are from Vention Lab

Support Huawei/ Xiaomi Fast Charge

5A(MAX) high current, Huawei FCP/
Qualcomm QC4.0 supported



100% 103 min
Full of Huawei P40



100% 75 min
Full of Xiaomi
10 Pro

Note: All data are from Vention Lab

Multiple Shielding Technologies

30/21AWG bold tinned copper conductor



Applicable USB-C Devices

	Laptop	Cellphone
Apple	MacBook12", MacBook Pro 2019 Mac Mini, MacBook Air 2020	Huawei Nova5/6/7 Mate20/30, Mate20/30 Pro Mate20/30 RS P20/30/40 P20/30/40 Pro
Huawei	MateBook, MateBook X/E MateBook 13/14	
Honor	MagicBook, MagicBook 2019	
Xiaomi	Air12.5"/13.3", GTX version 15.6" Xiaomi game book 8 generation	
HP	Pavilion x2, Spectre 13 EliteBook Folio G1, Envy 13 Shadow Wizard 4 Pro	Honor 30, 30S, V30 V20, Magic2 Note 10, V10
ASUS	Ling Yao 3, Ling Yao 3 Pro Ling Yao X series, U306, U321 U4100UN, U5100UQ, ROG	Microsoft Microsoft 950XL Microsoft 950
Dell	XPS13/15, Latitude 5285, G+C22 G3/G5/G7, Lingyue 5000/7000	Xiaomi 9/10 Pro, 9/10 8/9se, 8, 8 Lite Redmi Note7 Redmi K20/K30
Lenovo	Xiaoxin Air 12", Yoga5/6 Pro ThinkPad_X1 Carbon 2017 Saver Y7000/Y7000P/Y9000K	
SAMSUNG	NoteBook series GalaxyBook series	LG G5, V300L
Google	ChromeBook Pixels PixelBook Pen	Samsung S10, S10+, S10e A9s, A9 Stat Note8/9/10
Razer	Blade Stealth Spirit Blade Spirit Blade Sneak Edition	
Microsoft	Surface Book 2, Surface GO	Meizu 16/17th, X8
HTC	HTC 10	vivo Z5, iQOO, X27
Tablet	Apple iPad Pro 2018/2020	OPPO R17 Pro
	Huawei MediaPad M5	Smartisan Nut Pro 2S
	Xiaomi MI PAD 4	BlackShark BlackShark 2
Game console	Nintendo Switch	
More USB-C models will be continuously updated ...		

E-Marker Safety Chip

Ensures a well-protected charging environment



Fast Data Transmission

Standard USB2.0 interface

480Mbps

1G/30seconds



Note: All data are from Vention Lab

Multiple Lengths

Meet different needs

0.5m

Easy for carrying
around



1-1.5m

Daily charging
use



2m

Charging as well as
watching movie



Product Parameters

Brand: Vention	Shielding: Aluminum Foil+Metal
Name: USB 2.0 C Male to C Male	Braided
Dual Right Angle Cable 5A	Jacket: TPE+Nylon Braided
Model: TANH	AWG: 21+30AWG
Color: Gray	OD: 4.1mm
Interface: USB 2.0-C Male Right Angle	Length: 0.5/1/1.5/2m
Interface Technics: Nickel-plated	Rated Input: 5A
Transmission Rate: 480Mbps	Power Supply: PD100W (MAX)
Conductor: Tinned-copper	(20V/5A)
Shell: Aluminum Alloy	Warranty: 1 Year
Chip: E-Marker	Packing: PE Bag



Note: All data are from Vention Lab.
Sizes above are manually measured. There might be slight tolerance



Note: Packing difference exists for different meters or batches
The photo is for reference only

Length	Art.No.	EAN Code
0.5m	TANHD	6922794752566
1m	TANHF	6922794752573
1.5m	TANHG	6922794752580
2m	TANHH	6922794752597



Package Contents

USB 2.0 C Male to C Male Dual Right Angle 5A Cable

Packaging Information

Packing Dimension	cm
Packing Weight	kg
Carton Dimension	48*29*30cm
Carton Qty	300pcs(0.5m),250pcs(1m),200pcs(1.5m,2m)
Carton Weight	8kgs(0.5m), 10kgs(1m,1.5m), 12kgs(2m)
Package	PE bag