

Ratchet

2725

FINE GEAR 1/4"

- Reversible ratchet
- 8° gear action degree (45 teeth)

KT NO.	Overall length			
	inch	mm		
2725-55F	5-1/2	140	156	5 / 90
2725-55G	5-1/2	140	168	5 / 90
2725DK	renewal kits		-	-



2725DK



2725-55G



2725-55F

2755

 
FINE GEAR 1/4"

- Reversible ratchet
- 5° gear action degree (72 teeth)
- DIN 3122

KT NO.	Overall length			
	inch	mm		
2755-55G	5-1/2	144	113	5 / 90
2755DK	renewal kits		-	-



2755DK



2756


QUICK RELEASE FINE GEAR 1/4"

- Quick release reversible ratchet
- 5° gear action degree (72 teeth)
- DIN 3122

KT NO.	Overall length			
	inch	mm		
2756-55G	5-1/2	144	111	5 / 90
2756DK	renewal kits		-	-




 
2756DK



2752

QUICK RELEASE FINE GEAR 1/4"

 - Quick release flexible and reversible ratchet
- 5° gear action degree (72 teeth)
- Multi-angle design for difficult-to-reach fasteners

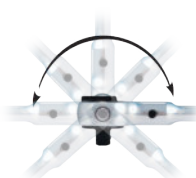

KT NO.	Overall length			
	inch	mm		
2752-06G	6	150	128	6 / 108
2752DK	renewal kits		-	-



2752DK

2752-45G

QUICK RELEASE FINE GEAR 1/4"

- Swivel head ratchet
- Quick release flexible and reversible ratchet
- 5° gear action degree (72 teeth)
- Application: T-handle ratchet / screwdriver ratchet

KT NO.	Overall length			
	inch	mm		
2752-45G	4-1/2	114	128	6 / 108

