


90 Teeth Dustproof Ratchet **PAT.**



- Material
 - chrome vanadium alloy steel handle
 - chrome molybdenum steel (gear) driver
- Finishing
 - polished, chrome plated
 - black driver by phosphate sunk

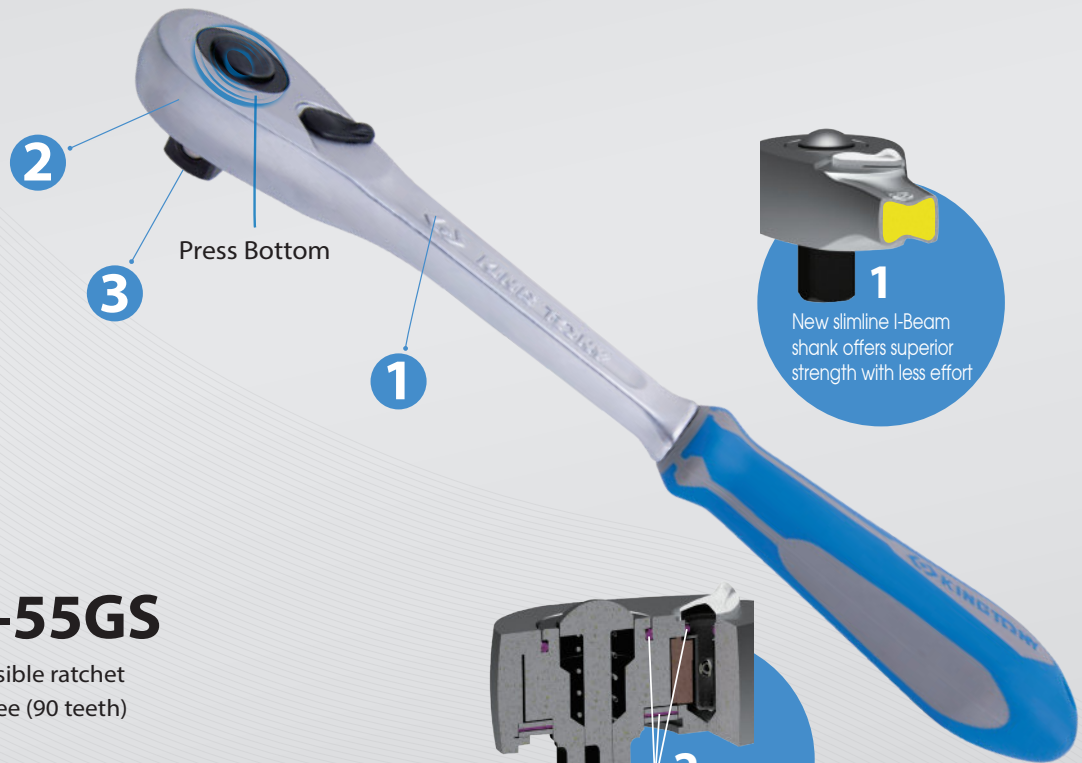

1
New slimline I-Beam
shank offers superior
strength with less effort

2773-55GS

- Quick release reversible ratchet
- 4° gear action degree (90 teeth)
- DIN 3122
- IP51

KT NO.	Square DR.	Overall length			
		inch	mm		
2773-55GS	1/4"	5-1/2	140	110	1 / 100
2773DK				renewal kits	



2773DK



2
Dustproof -
Double Sealing
gasket

4773-10GS (IP51)



3
Screwless design -
Easy to repair