
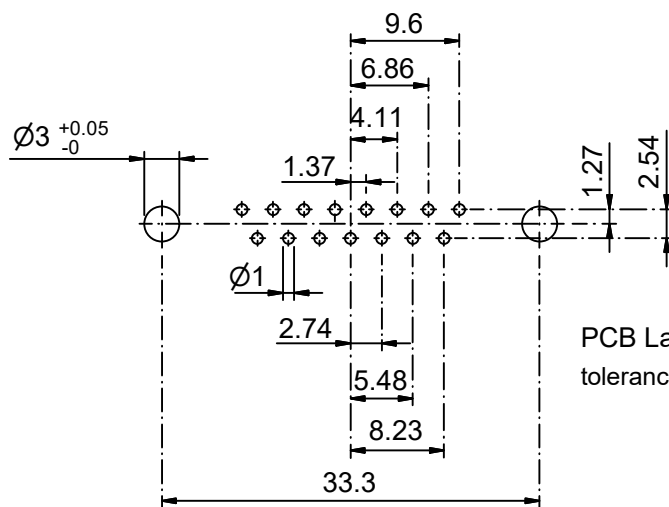
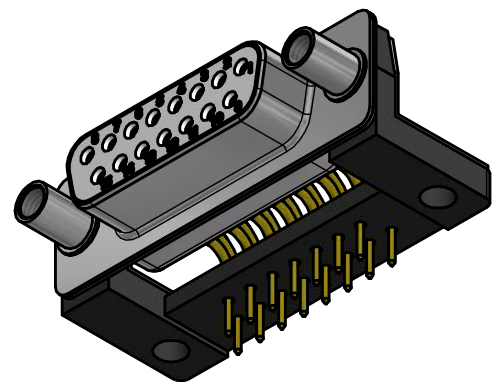
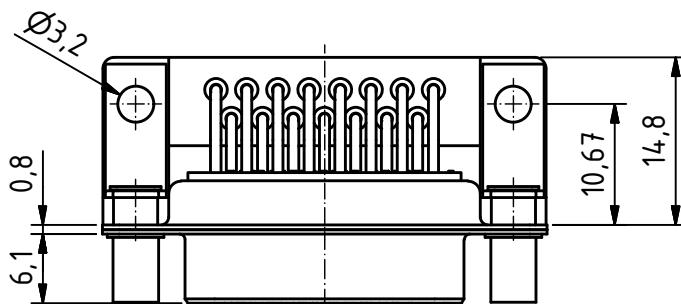
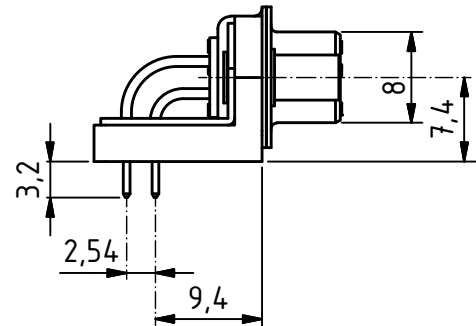


RoHS compliant

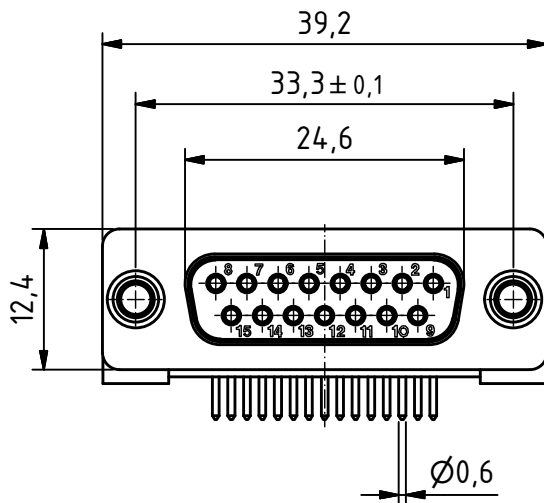

PCB Layout
tolerances +/-0.1

MATERIALS

- Insulator: Thermoplastic UL 94-V-0 white
- Contact: Machined / Copper alloy
- Contact finish: Quality class 2
- Shell: steel tin plated

CHARAKTERISTICS

- Working voltage: 125V
- Current rating: 7.5A
- Contact resistance: max. 10mΩ - DIN41652
- Insulation resistance: >5GΩ
- Temperature range: -55° to +125°C

General tolerances (Delttron standard)				
size in mm		tolerances		
> 0.5	> 3	> 6	> 30	
up to 3	up to 6	up to 30	up to 120	
±0.1	±0.2	±0.2	±0.3	

modification	Rev.	Rev.	Rev.	DE002563		
	Rev.	Rev.	Rev.	part no.		
DTS15SYC/2M66UN	1.5:1 scale		drawn	19.04.2013	mr	
			checked			
			approved			
		Industrie Neuhof 8c CH-3422 Kirchberg www.d-sub.swiss		K061352 drawing no.		