
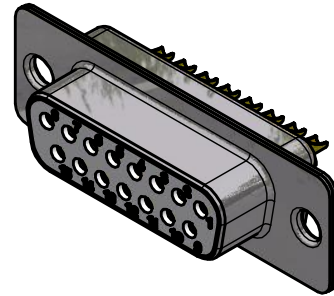
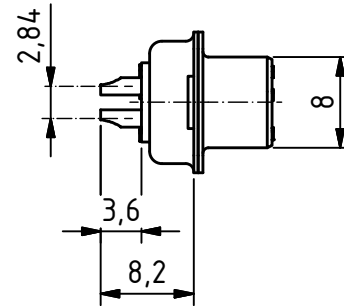


RoHS compliant

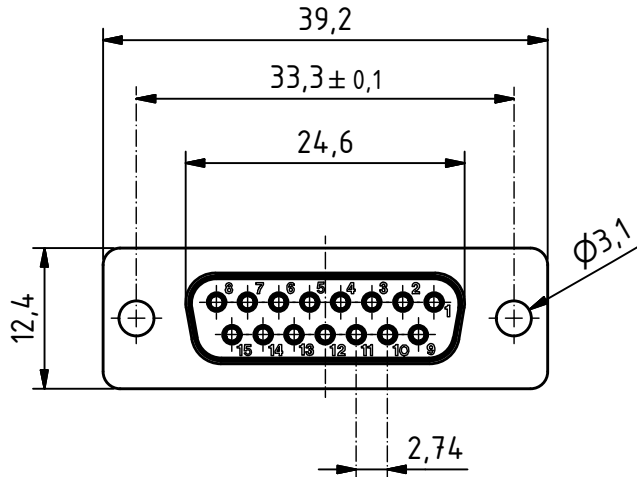

suitable for cable AWG 18 (single solid wire)

 
MATERIALS

- Insulator: Thermoplastic UL 94-V-0 white
- Contact: Machined / Copper alloy
- Contact finish: Quality class 2
- Shell: steel tin plated

CHARAKTERISTICS

- Working voltage: 125V
- Current rating: 7.5A
- Contact resistance: max. 10mΩ - DIN41652
- Insulation resistance: >5GΩ
- Temperature range: -55° to +125°C

General tolerances (Deltron standard)				
size in mm	tolerances			
	> 0,5 up to 3	> 3 up to 6	> 6 up to 30	> 30 up to 120
	±0,1	±0,2	±0,2	±0,3

	All dimensions in mm	Rev.	Rev.	Rev.	DE002179		
		Rev.	Rev.	Rev.	part no.		
DTS15SZ/2				1.5:1 scale	drawn	10.11.2009	mr
					checked		
					approved		
				K050008 drawing no.			
Industrie NeuhoF 8c CH-3422 Kirchberg www.d-sub.swiss							