



RoHS compliant

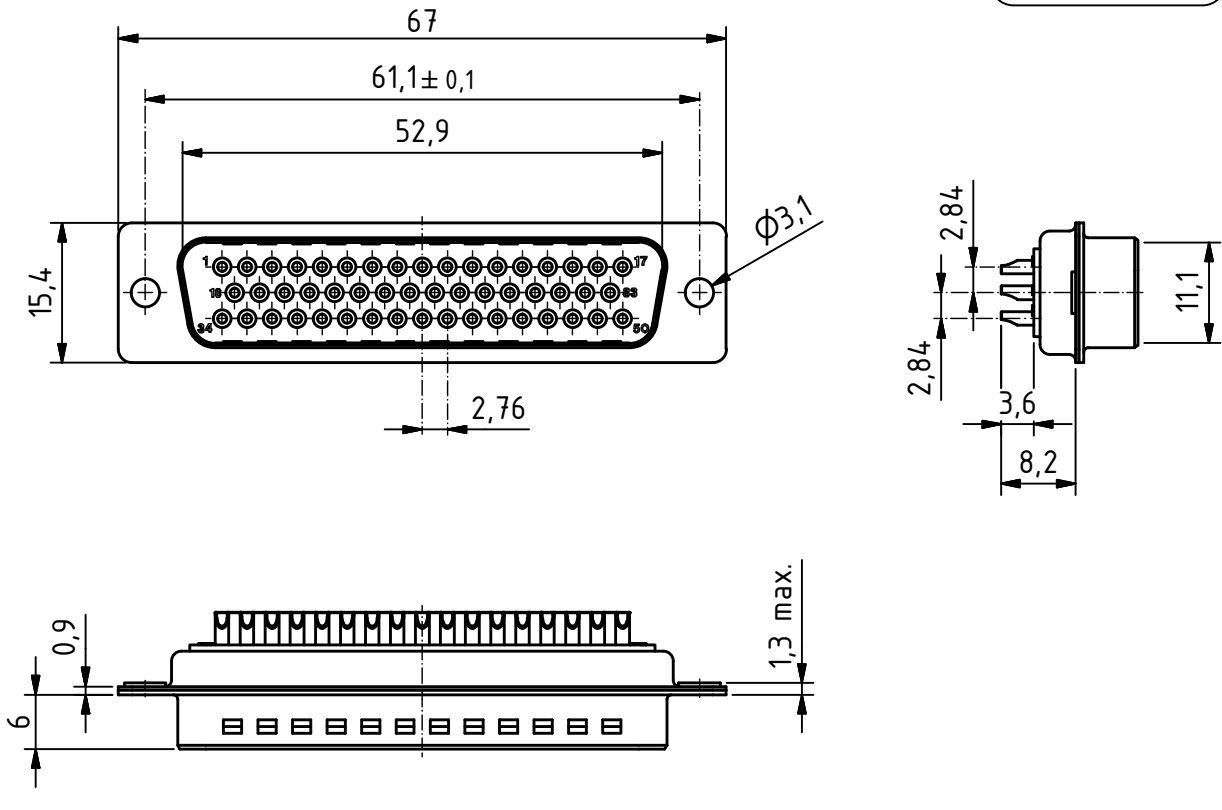

suitable for cable AWG 18 (single solid wire)

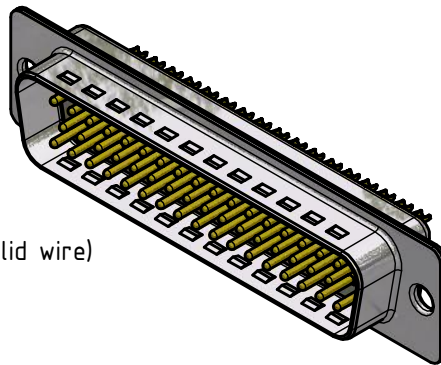

 
MATERIALS

- Insulator: Thermoplastic UL 94-V-0 white
- Contact: Machined / Copper alloy
- Contact finish: Quality class 2
- Shell: steel tin plated

CHARAKTERISTICS

- Working voltage: 125V
- Current rating: 7.5A
- Contact resistance: max. 10mΩ - DIN41652
- Insulation resistance: >5GΩ
- Temperature range: -55° to +125°C

General tolerances (Deltron standard)			
size in mm	tolerances		
	> 0.5 up to 3	> 3 up to 6	> 6 up to 30 up to 120
	±0.1	±0.2	±0.3

	All dimensions in mm	Rev. a) 29.03.2010 mr	Rev.	Rev.	DE001232		
		Rev.	Rev.	Rev.	part no.		
DTS50PZ/2				1.2:1 scale	drawn	27.01.1998	mr
					checked		
					approved		
				Industrie NeuhoF 8c CH-3422 Kirchberg <u>www.d-sub.swiss</u>			K050019 a drawing no.