




CAT6 SFTP Patch Cord Cable

C A T 6 G I G A B I T E T H E R N E T C A B L E

Faster Speed Ethernet Cable

CAT 6 1000Mbps

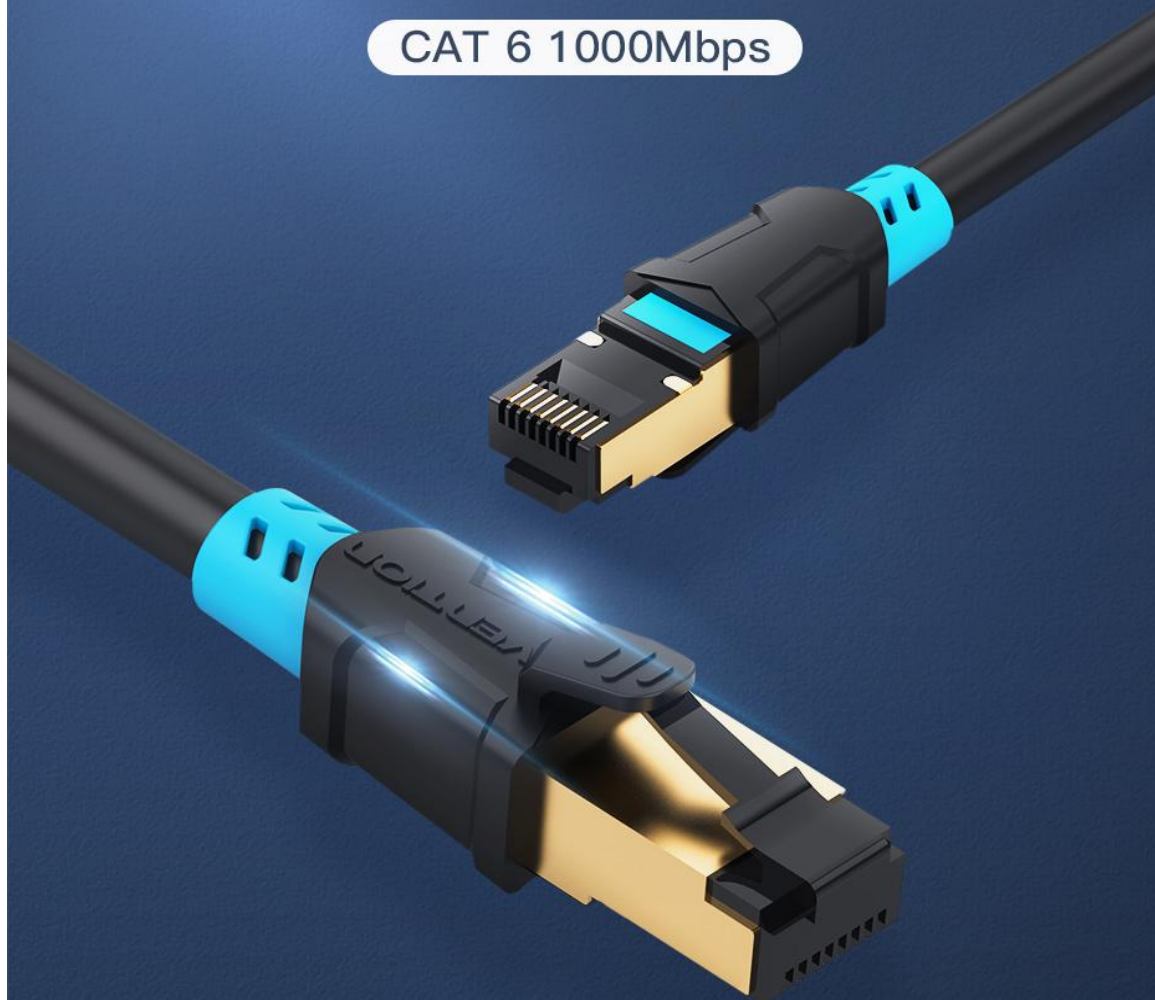

Fast
Download

Gold Plated
Contacts

Twisted
Pairs

Gigabit Ethernet Access

Up to 1000Mbps transmission rate



Online Game



Fast Download




HD Video




Universal Compatibility

For all devices with RJ45 Network Interface

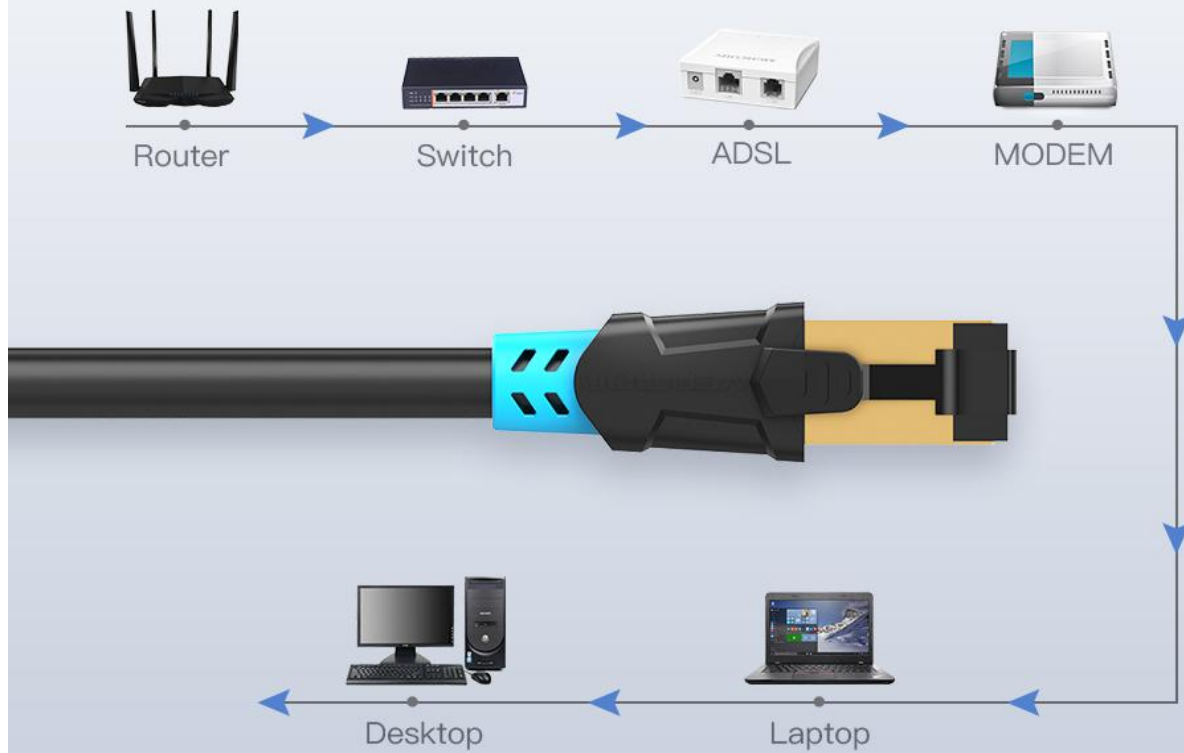

Double Shielding

8-core twisted pair structure provides less signal losses

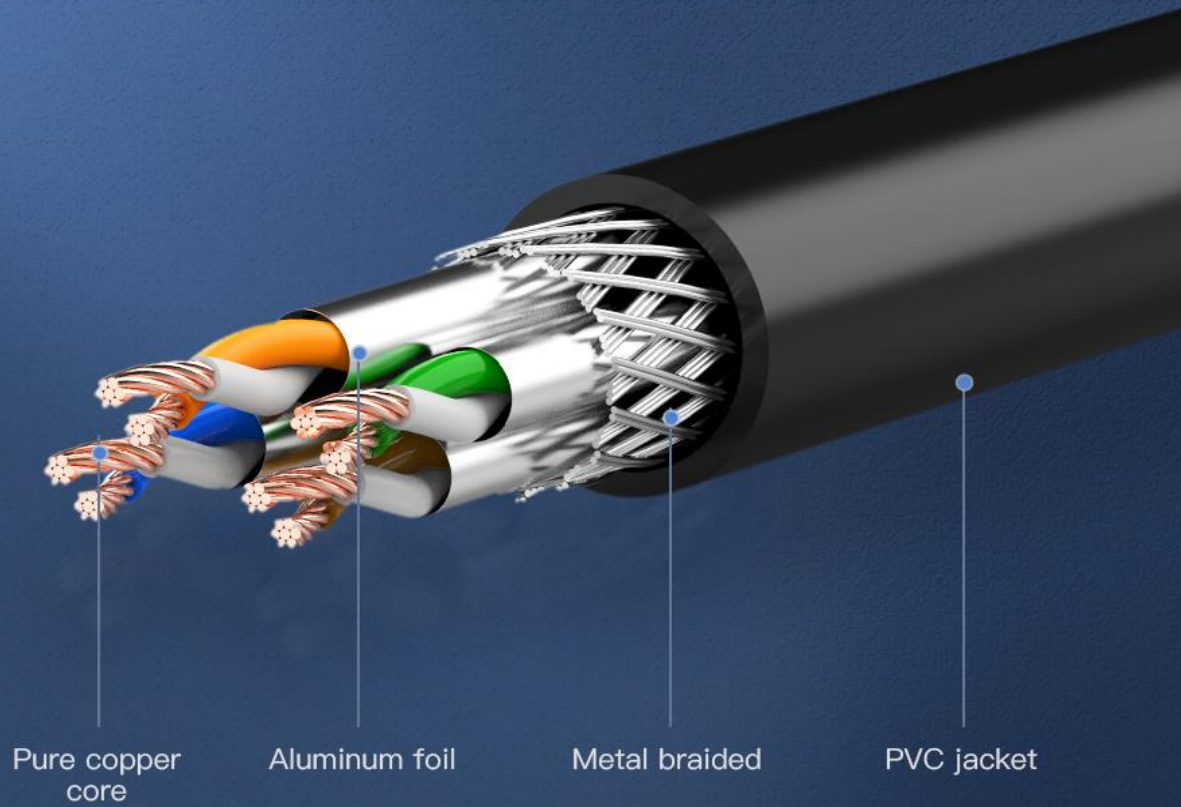


Soft and Strong Cable

Environment PVC line body, ensure longer service life



Gold Plated Contacts


Highly wear resistant, ensure stable transmission

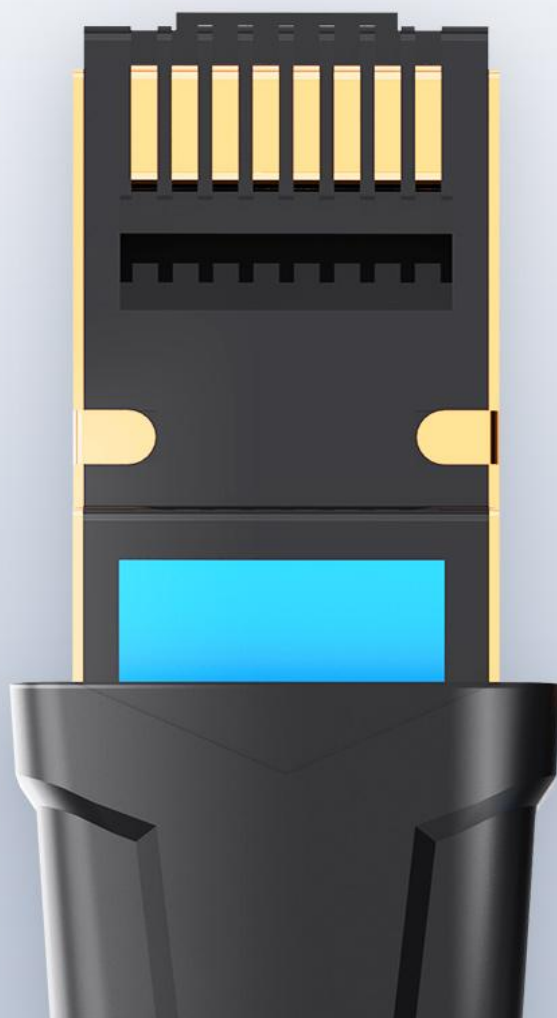

Product Parameters

Brand	Vention
Name	CAT6 Gigabit Ethernet Cable
Model	VAP-A06
Appearance Color	Black/Blue
Interface Type	RJ45
Conductor	Pure Copper
Core	8-core Twisted Pair
Shield	Aluminum Foil + Metal Braided
Transmission Rate	1000Mbps
Broadband	250MHz
Warranty	One Year
Packing	PE Bag

* All data are from Vention laboratory

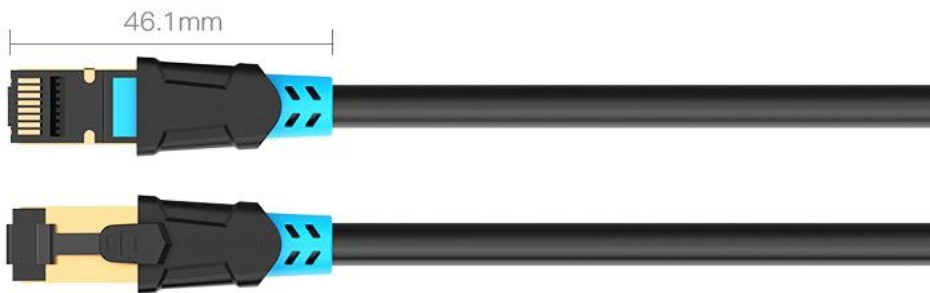

* Sizes above are hand measurement, there might be slight tolerance

Length	Art.No.	EAN Code
0.75m	VAP-A06-B075	6922794729322
1m	VAP-A06-B100	6922794729339
1.5m	VAP-A06-B150	6922794729346
2m	VAP-A06-B200	6922794729353
3m	VAP-A06-B300	6922794729360
5m	VAP-A06-B500	6922794729377
8m	VAP-A06-B800	6922794729384
10m	VAP-A06-B1000	6922794729391
15m	VAP-A06-B1500	6922794729414
20m	VAP-A06-B2000	6922794729421
25m	VAP-A06-B2500	6922794729438
30m	VAP-A06-B3000	6922794729445
35m	VAP-A06-B3500	6922794729452



Package Contents

CAT6 SFTP Patch Cord Cable

Packaging Information

Packing Dimension	cm
Packing Weight	kg
Carton Dimension	48*29*30(0.75-15m), 46*40*40(20m), 52*46.5*24.5(25m-35m)
Carton Qty	120pcs(0.75m, 1m), 100pcs(1.5m) , 80pcs(2m),60pcs(3m),50pcs(5m) ,40pcs(8m),30pcs(10m),25pcs(15m),28pcs(20m),12pcs(25m-35m)
Carton Weight	5.5kgs(0.75m), 7kgs(1m-3m), 9.5kgs(5m),11.5kgs(8m,25m),10kgs(10m), 13kgs(15m),21kgs(20m),12kgs(25m),14kgs(30m),16kgs(35m)
Package	PE Bag/Color Box

www.ventiontech.com