




Cat.8 SFTP Extension Patch Cable

Cat.8

SFTP Extension Patch Cable

—
Solve the problem that
the network cable is not long enough

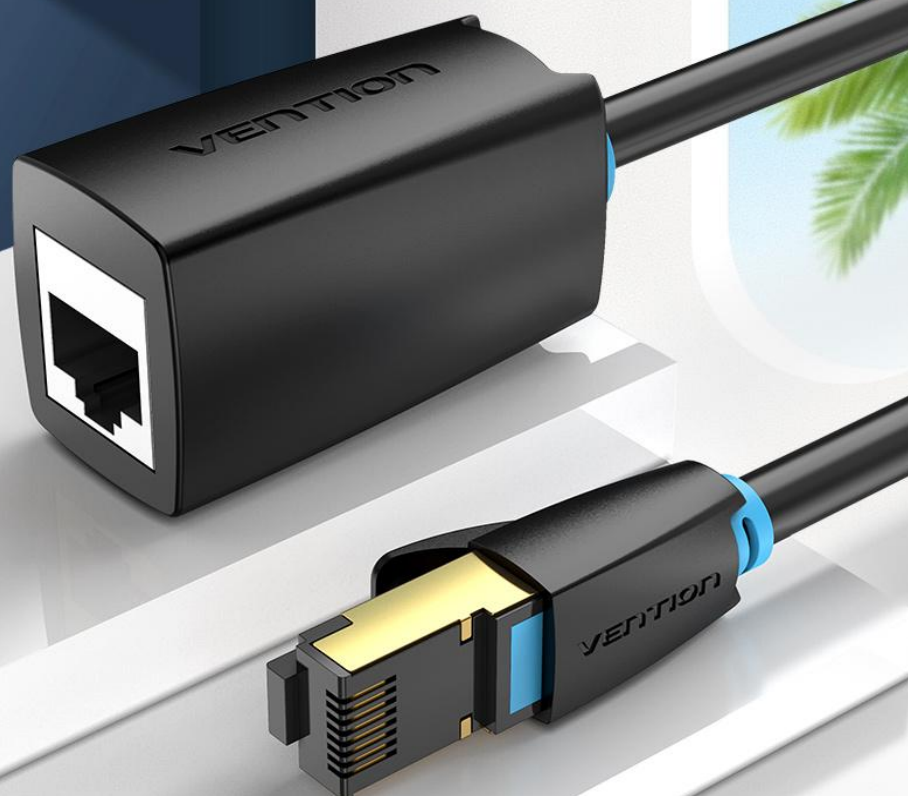

40Gbps
2000MHz

Oxygen-free
copper
Twisted pairs

Double
aluminum
foil shield

POM
Gold-plated
copper shell

Extended at Will

Easily solve the problem that the network cable is not long enough when embedded

0.5_m

|

10_m




40Gbps Transfer Rate

Vastly improve your Lan throughput

40
Gbps

2000
MHz

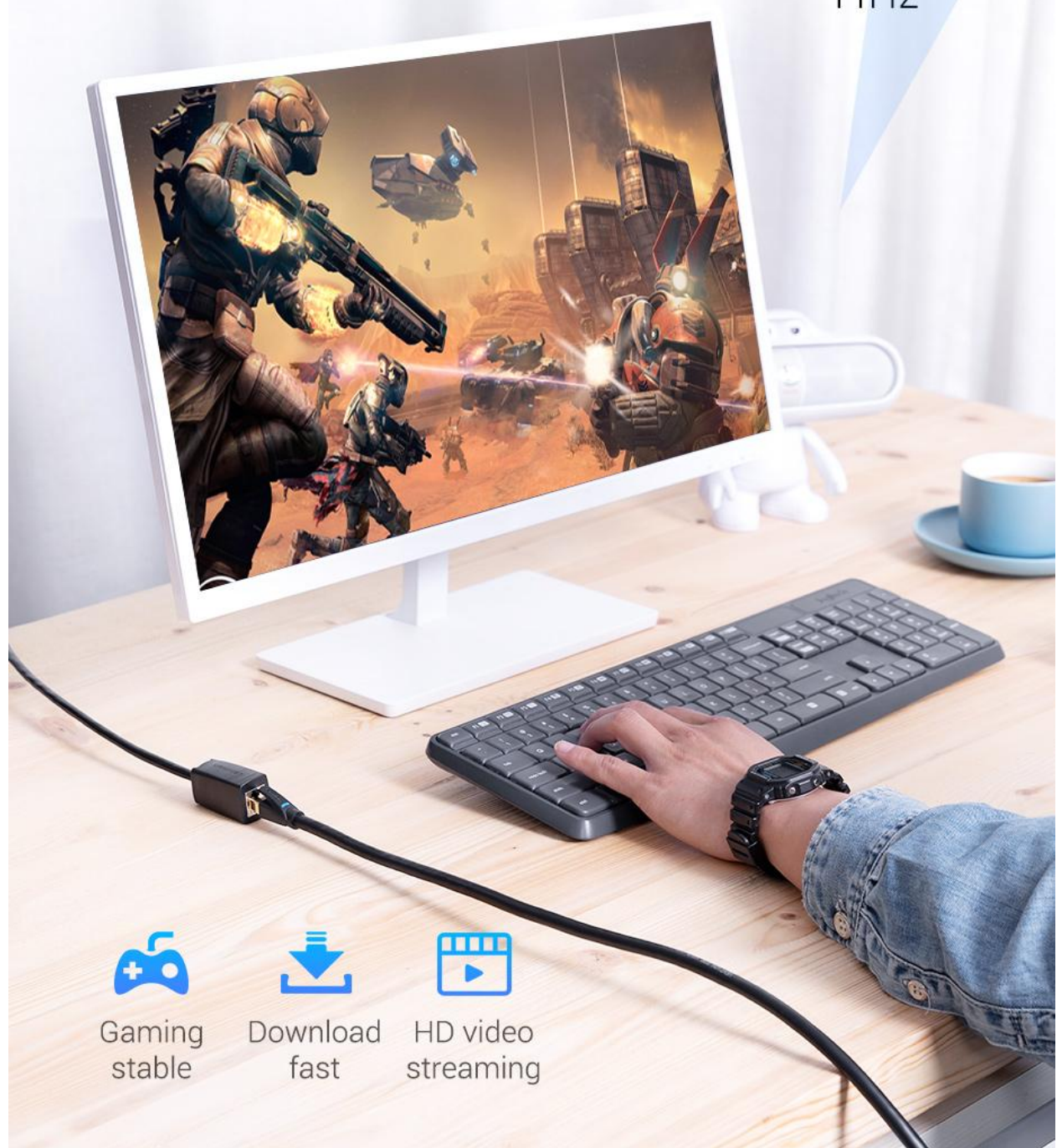

Gaming
stable



Download
fast



HD video
streaming

The Coming 5G Era

Type	Rate	Bandwidth	Distance	Cable type	Application
Cat.8	40Gbps	2000MHz	30m	Double shield	High-speed bandwidth environment
Cat.7	10Gbps	600MHz	100m	Double shield	High-speed bandwidth environment
Cat.8 6A	10Gbps	500MHz	100m	Shielded / Unshielded	Large enterprises / High-speed applications
Cat.6	1000Mbps	250MHz	100m	Shielded / Unshielded	Large enterprises / High-speed applications
Cat.5E	100Mbps	155MHz	100m	Shielded / Unshielded	Small Office / Home
Cat.5	100Mbps	100MHz	100m	Shielded / Unshielded	Small Office / Home

Note: The actual use data may be restricted by the environment of routers, switches, network providers and other equipments

Five Upgrades

Upgrade 1


Bold Copper Conductor Twisted Pairs

26

AWG
oxygen-free
copper


4 pairs

of twisted
pair structure

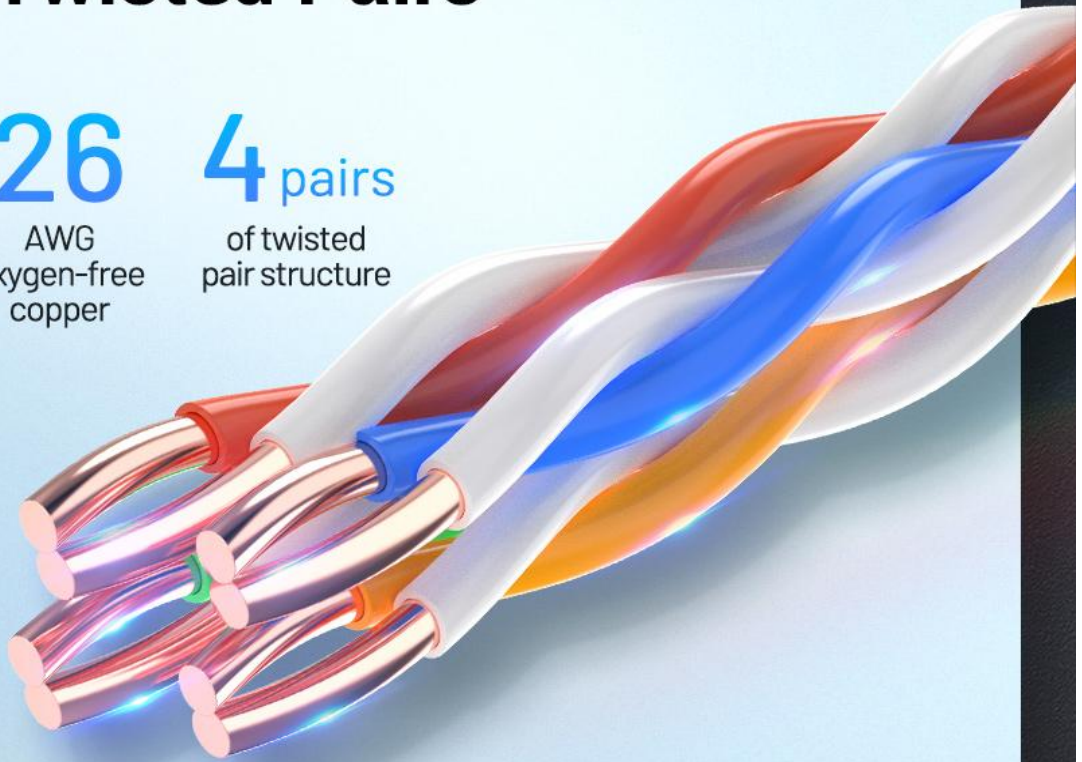

Upgrade 2

Double Shield Stable Network

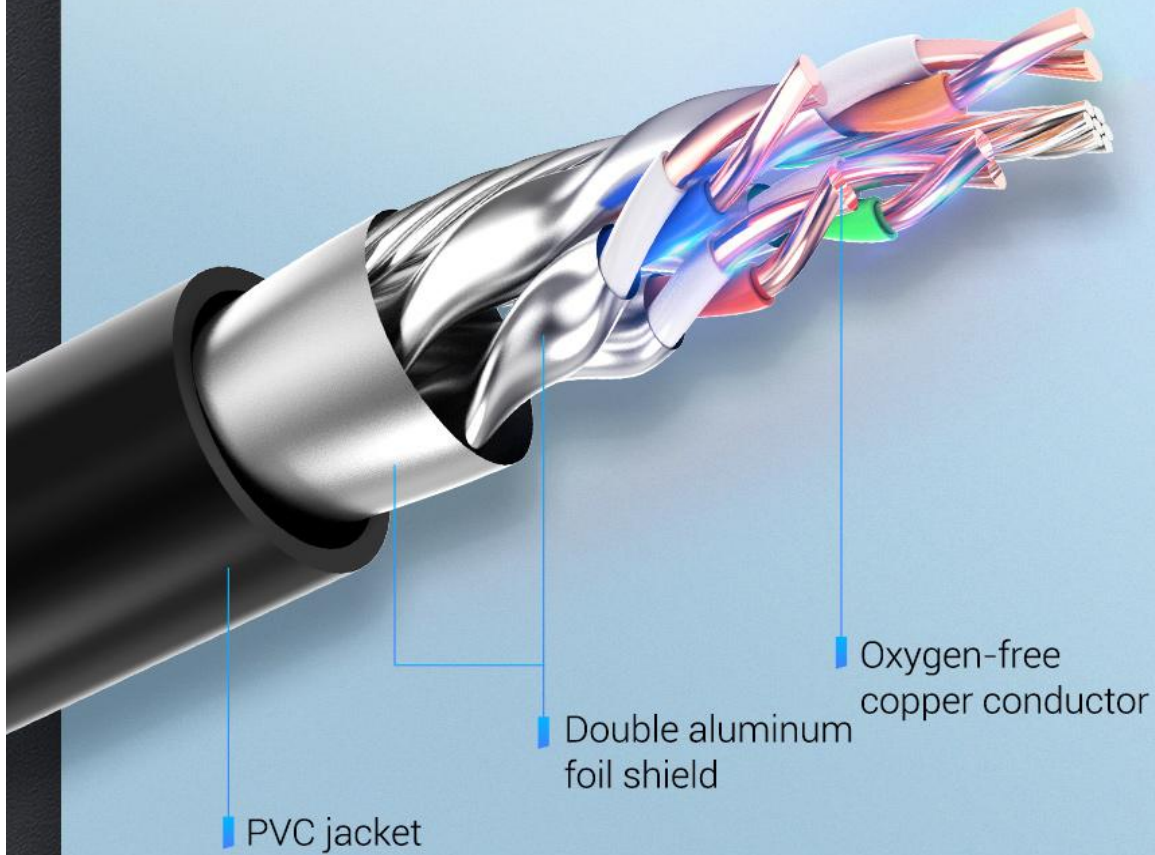


Upgrade 3

Unusual RJ45 Plug

Black POM

Enhanced
ramp protector

Gold-plated
copper shell

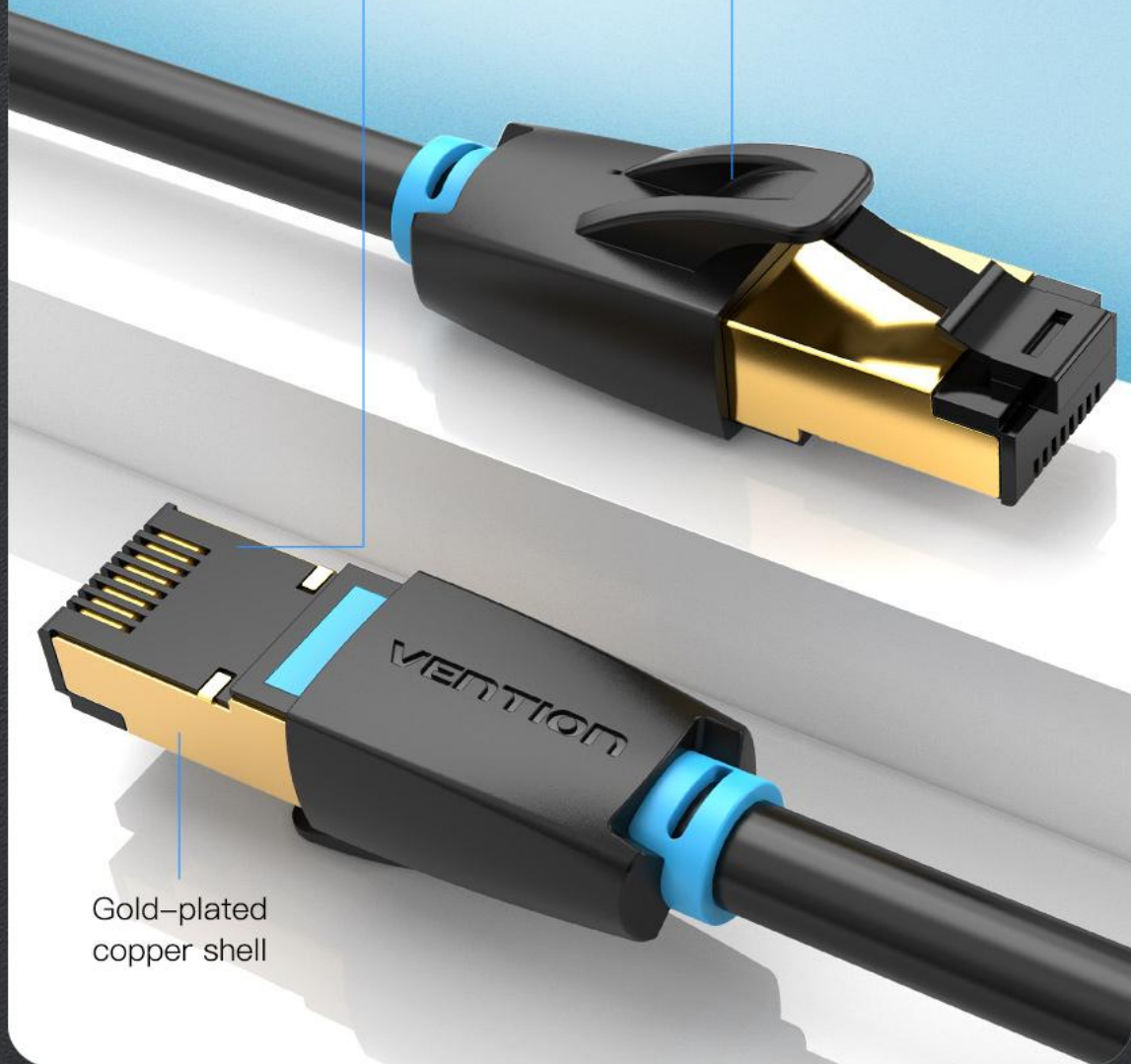

Upgrade 4

Gold-plated Contacts

Wear-resistant and strongly
enhance transmission speed



Multiple Devices&Application



Desktop



Laptop



Router



Switch



TV



Set-top box



Home



Office



Internet cafe



Hotel/Apartment

FLUKE Networks Test

Meet the Cat.8 network cable standards



Multiple Length


0.5m



10m

Product Parameters

Brand: Vention	Conductor: Oxygen-free Copper
Name: Cat.8 SFTP Extension Patch Cable	Shielding: Double Aluminum Foil
Model: IKH	Jacket: PVC
Color: Black	AWG: 26AWG
Interface: RJ45	OD: 6mm
Transmission Rate: 40Gbps	Length: 0.5/1/1.5/2/3/5/8/10m
Transmission Bandwidth: 2000MHz	Warranty: 1 Year
Interface Technics: POM	Packing: PE Bag
Shield Shell: Gold-plated Copper Shell	
Connector Chips Technics: Pure Copper Gold-plated 30U Trigeminal Chip	

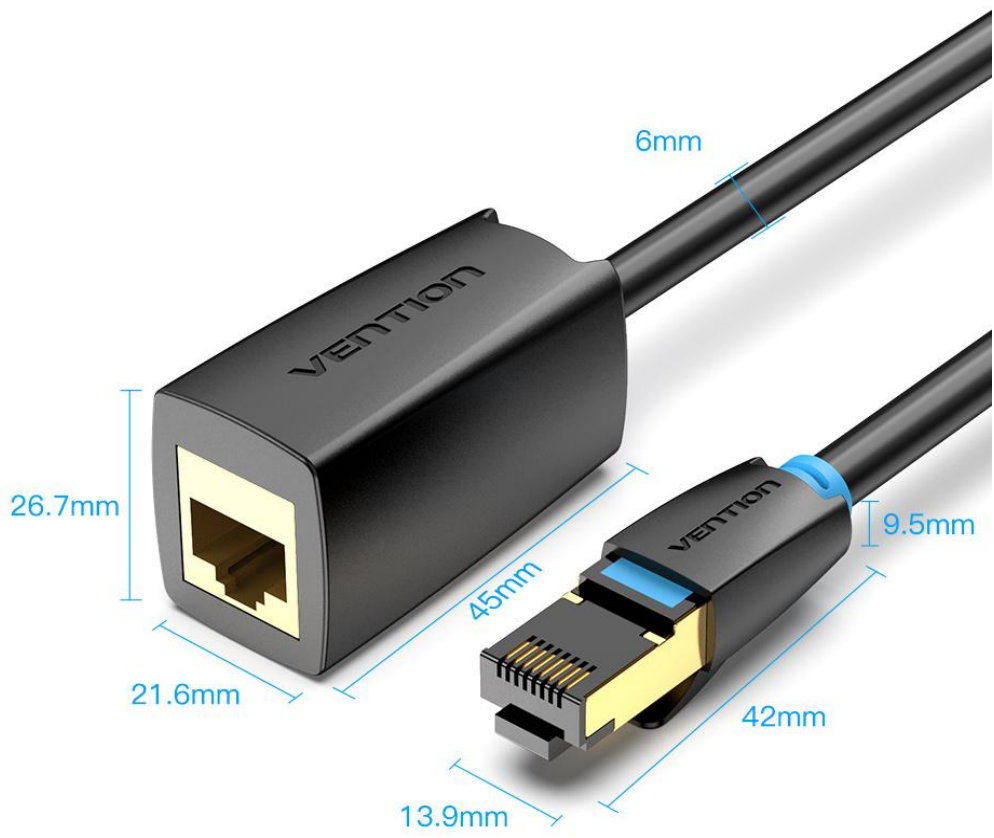

Note: All data are from Vention Lab.
Sizes above are manually measured. There might be slight tolerance.



Note: Packing difference exists for different meters or batches.
The photo is for reference only.

Length	Art.No.	EAN Code
0.5m	IKHBD	6922794744929
1m	IKHBF	6922794744936
1.5m	IKHBG	6922794744943
2m	IKHBH	6922794744950
3m	IKHBI	6922794744967
5m	IKHBJ	6922794744974
8m	IKHBK	6922794744981
10m	IKHBL	6922794744998



Package Contents

Cat.8 SFTP Extension Patch Cable

Packaging Information

Packing Dimension	cm
Packing Weight	kg
Carton Dimension	48*29*30
Carton Qty	150pcs(0.5m),260pcs(1m),100pcs(1.5m),80pcs(2m),50pcs(3m), 42pcs(5m), 30pcs(8m), 25pcs(10m)
Carton Weight	10kgs(0.5m,2m, 5m, 8m,10m), 23kgs(1m)),11kgs(1.5m), 8kgs(3m)
Package	PE Bag