


MINI ROTARY TOOL KIT



Power	135 W
Voltage	230 V / 50 Hz
No-load speed	8000-33000 RPM
Weight	640 g
Cable	2 m

ref.	description	☐	ean
PG138W	- ergonomically designed housing for comfortable gripping - powerful motor and variable speed for increased versatility - includes 5 assorted collets (ø 1,6 - 2,35 x2 - 3,0 - 3,2 mm), 1 nut and 1 wrench - 350 assorted accessories - flexible shaft 110 cm	1	071428

MINI ROTARY TOOL

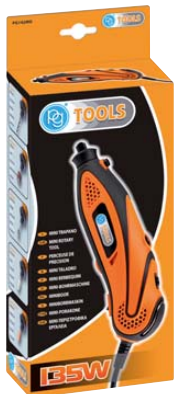

Power	135 W
Voltage	230 V / 50 Hz
No-load speed	10000-32000 RPM
Weight	650 g
Cable	1,8 m

ref.	description	☐	ean
PG142MD	- ergonomically designed housing for comfortable gripping - powerful motor and variable speed for increased versatility - includes 3 assorted collets (ø 1,6 - 2,35 - 3,2 mm), 1 nut and 1 wrench	1	071053

MINI FLEXIBLE SHAFT



ref.	description	☐	ean
M.8505	- includes 3 assorted collets (ø 2,35 - 3,0 - 3,2 mm), 1 nut and 1 wrench - length 105 cm - 30000 RPM	1	071060

ASSORTED ACCESSORIES FOR MINI POWER TOOLS



ref.	description	☐	ean
PG195A	kit 195 accessories	1	071077

ASSORTED ACCESSORIES FOR MINI POWER TOOLS



ref.	description	☐	ean
PG290A	- kit 290 accessories in modular plastic anti-shock box with anti-slip reinforcements - dimensions 16,5 x 12 x 6,5 cm	1	071435

HOT AIR GUN KIT



Power	2000 W
Voltage	230 V / 50 Hz
Air volume	300/500 l/m
Air temperature	350/550 °C
Weight	560 g
Cable	2 m

ref.	description	☐	ean
PGPT2000	- adjustable temperature - including 5 assorted accessories	1	088587