




USB 2.0 A Male to 2-in-1 Micro-B&USB-C Male Cable

# 2-IN-1 USB 2.0 CHARGING CABLE

Micro-B/USB-C interfaces

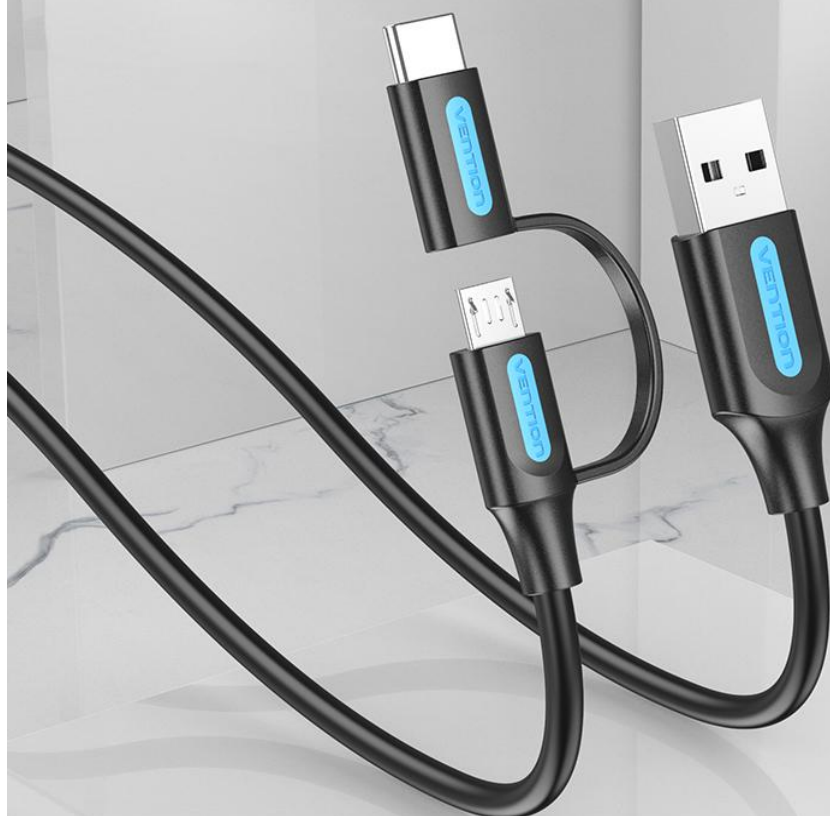

2A high current  
USB to Micro-B

Micro-B/USB-C  
Power bank

3A high current  
USB to USB-C

Wide compatibility  
Flexible transfer

# Less Charging Time

Micro-B support 2A current  
USB-C support 3A high current  
significantly cut down charging time



**113min**  
Full of Huawei P40

**3800mAH**  
capacity



Around **120 min**  
Full of Xiaomi Play

**3000mAH**  
capacity

Note: all data are from Vention Lab

# Two Interfaces Available

Support Micro-B/USB-C interface devices



**Micro-B interface:** applicable for android phone, tablet, mobile HDD, desk fan


**USB-C interface:** applicable for Huawei, Xiaomi, Samsung, etc., laptop and tablet

# Charging Power Bank

Support USB-C/Micro USB interface power bank charging

Around **5** hours

Full 10000mAh power bank

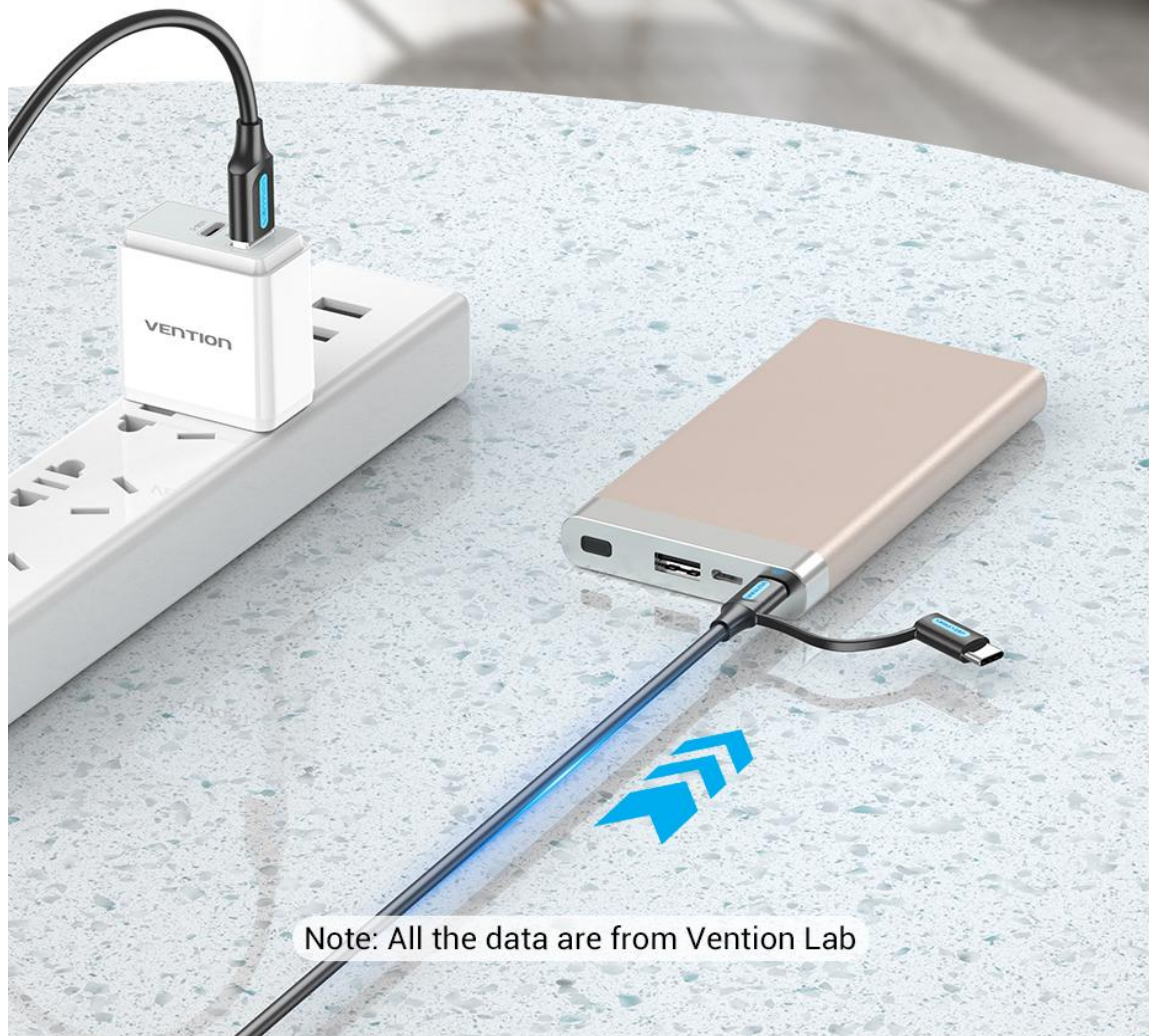

Note: All the data are from Vention Lab

# Support Various Charging Protocols

Support Samsung, Xiaomi, Qualcomm, etc. charging protocols




**100 min**

Full of Xiaomi 10 Pro

**4500 mAH**


capacity

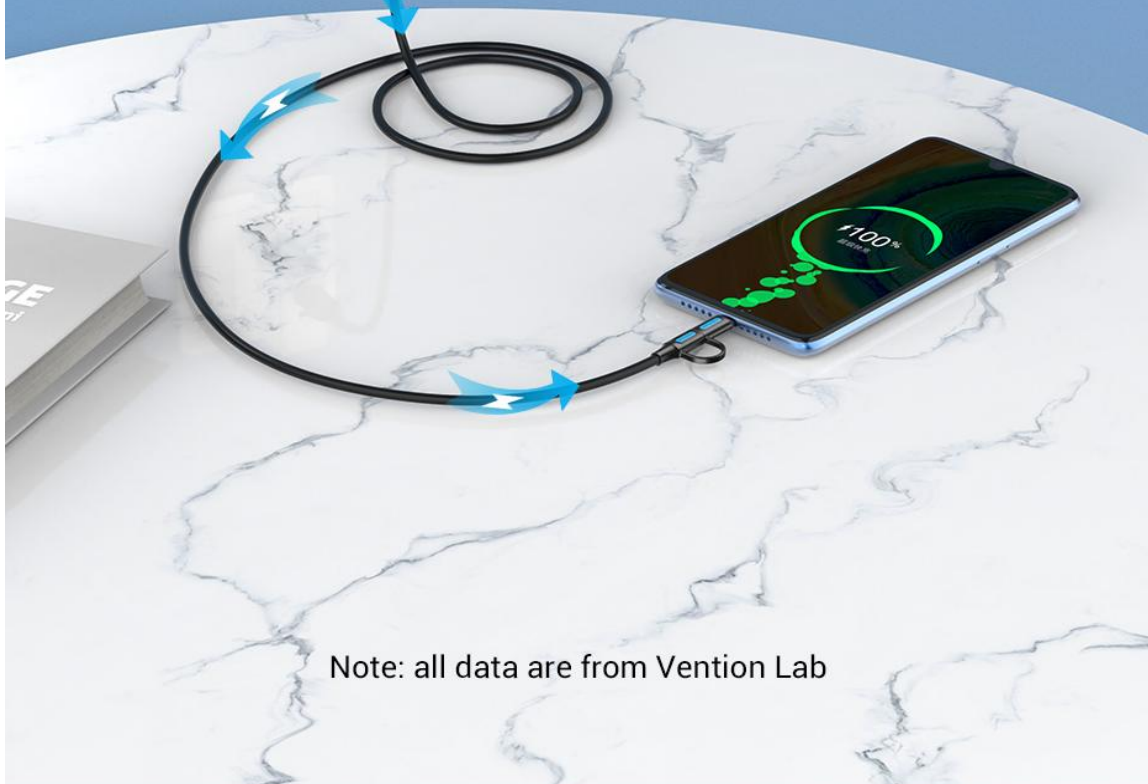

Note: all data are from Vention Lab

# Safeguard Your Battery

Thickened tinned-copper conductor with multiple shielding technologies for battery protection

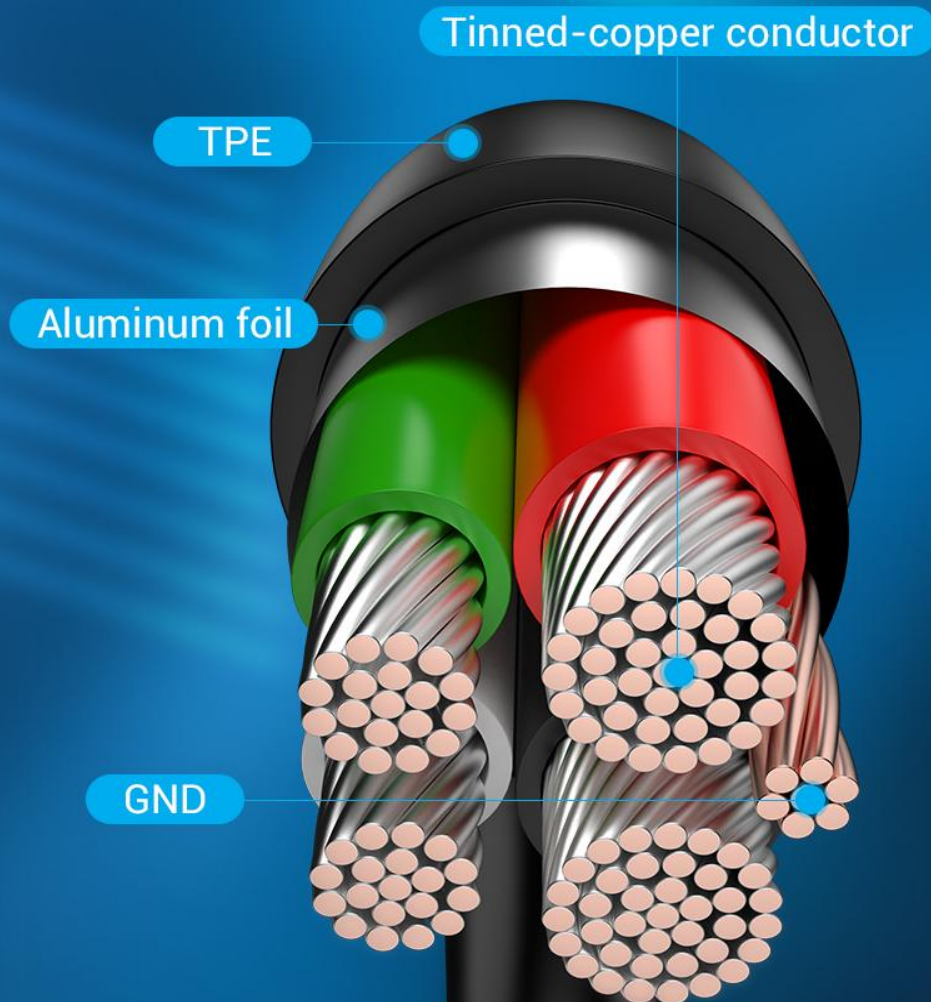

Note: the internal structure is a rendering, please in kind previal

# Smooth Plug in/out

One-piece moulding design  
more swapping times

**3000+**  
USB interface swapping test

**10000+**  
USB-C interface swapping test

**10000+**  
Micro-B interface swapping test



Note: all data are from Vention Lab

# USB2.0 Standard

480Mbps transmission rate, 1 GB file within 30 secs



Note: all data are from Vention Lab

# Applicable Devices List

|                                              | USB-C interface<br>phone/tablet                                                           | Micro USB interface<br>phone                                                                  |
|----------------------------------------------|-------------------------------------------------------------------------------------------|-----------------------------------------------------------------------------------------------|
| <b>Huawei</b>                                | nova 7,nova 7 SE,<br>nove 7 Pro, Mate 30, Mate 30 Pro,<br>nova 6, nove 6 Pro, nova 5      | nova 3i, nova lite, Manmao 6<br>Mate8, Enjoy 9,9 Plus<br>MAX, 8,8 Plus, 8e lite, 8e           |
|                                              | MediaPad M5                                                                               |                                                                                               |
| <b>Honour</b>                                | 30, 30 Pro,<br>V30, V30 Pro, V20                                                          | 8X, 9l, 9 Lite, 8 Lite, V9 Play<br>7l, Holloy 8C, 7X, 7C, 7, 7A<br>6X, 6A, 6<br>5X, 5A, 5, 5C |
| <b>Xiaomi</b>                                | 10 Pro, 10, 9 Pro, 9, 9 SE<br>8, 8 Lite, 8 SE<br>Redmi K30 Pro, Redmi K30<br>Redmi Note 7 | Play, 4, 6, 6 Pro, 6A<br>Note 5, Note 5A, 5, 5A<br>5 Plus, Note 4, Note 4X                    |
|                                              | MI PAD 4                                                                                  |                                                                                               |
| <b>Samsung</b>                               | S10, S10+, S10E<br>A9S, A9 STAR<br>A6S, A8S, S9, S9+, Note9                               | S6, A7                                                                                        |
| <b>Meizu</b>                                 | 16th, 17th, 16th and 16th                                                                 | V8, NOTE8, ML NOTE6, 6, S6<br>NOTE5, 5, 6T, A5, 5s<br>NOTE3, MAX, U20, U10, E2                |
| <b>Smartisan</b>                             | Pro 2S, R1                                                                                |                                                                                               |
| Note: this list will be continuously updated |                                                                                           |                                                                                               |

# Delicate Details

Nickel-plated interface  
Anti-rust and antioxidant

Extra long tail  
Bending resistance

TPE jacket  
Wear resistance



# Product Parameters

**Brand:** Vention

**Name:** USB 2.0 A Male to 2-in-1 Micro-B&USB-C Male Cable

**Model:** CQDB

**Color:** Black

**Interface:** USB 2.0 C Male/USB 2.0 A Male/USB 2.0 Micro-B Male

**Interface Technics:** Nickel-plated

**Transmission Rate:** 480Mbps

**Conductor:** Tinned-copper

**Shell:** PVC

**Shielding:** Aluminum Foil+GND

**Jacket:** TPE

**AWG:** 22+28AWG

**OD:** 4.0mm

**Length:** 0.25/0.5/1/1.5/2m

**Rated Current:** Micro USB: 2A, USB C: 3A (Max)

**Warranty:** 1 Year

**Packing:** PE Bag



Note: All data are from Vention Lab.

Sizes above are manually measured. There might be slight tolerance



Note: Packing difference exists for different meters or batches.  
The photo is for reference only

| Length | Art.No. | EAN Code      |
|--------|---------|---------------|
| 0.25m  | CQDBC   | 6922794753013 |
| 0.5m   | CQDBD   | 6922794753020 |
| 1m     | CQDBF   | 6922794753037 |
| 1.5m   | CQDBG   | 6922794753044 |
| 2m     | CQDBH   | 6922794753051 |
|        |         |               |
|        |         |               |
|        |         |               |
|        |         |               |
|        |         |               |
|        |         |               |
|        |         |               |
|        |         |               |
|        |         |               |



**Package Contents**

USB 2.0 A Male to 2-in-1 Micro-B&USB-C Male Cable

**Packaging Information**

|                   |                                                        |
|-------------------|--------------------------------------------------------|
| Packing Dimension | cm                                                     |
| Packing Weight    | kg                                                     |
| Carton Dimension  | 48*29*30                                               |
| Carton Qty        | 500pcs(0.25m),300pcs(0.5m),200pcs(1m,1.5m), 150pcs(2m) |
| Carton Weight     | 7.5kgs(0.5m,1m), 8kgs(2m), 9kgs(1.5m), 10kgs(0.25m)    |
| Package           | PE Bag                                                 |