


CAT6 SFTP Patch Cord Cable

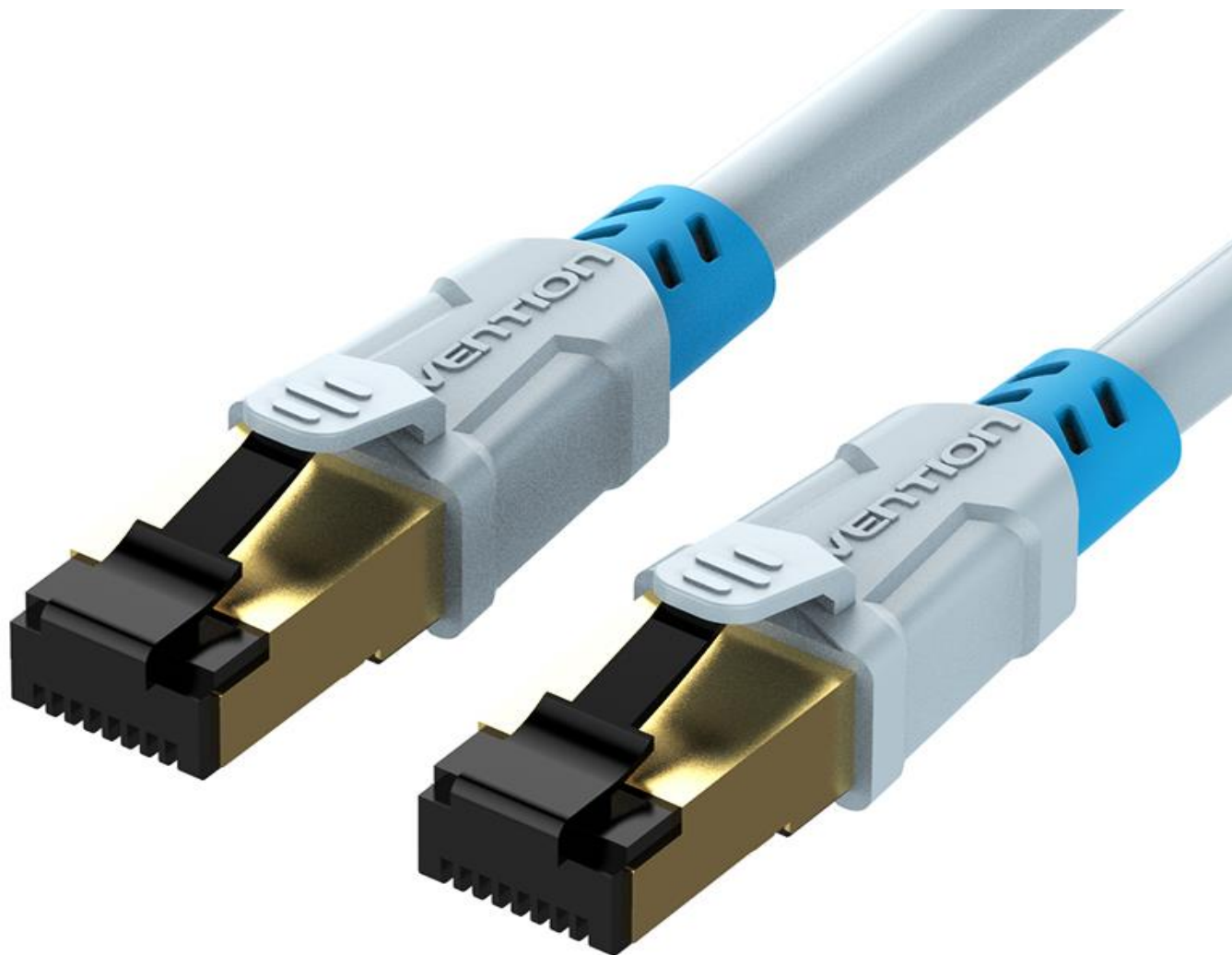


Product Parameters

Brand	Vention
Name	CAT6 Gigabit Ethernet Cable
Model	VAP-A06
Appearance Color	Black/Blue
Interface Type	RJ45
Conductor	Pure Copper
Core	8-core Twisted Pair
Shield	Aluminum Foil + Metal Braided
Transmission Rate	1000Mbps
Broadband	250MHz
Warranty	One Year
Packing	PE Bag

* All data are from Vention laboratory

Length	Art.No.	EAN Code
0.75m	VAP-A06-S075	6922794714267
1m	VAP-A06-S100	6922794714274
1.5m	VAP-A06-S150	6922794714281
2m	VAP-A06-S200	6922794714298
3m	VAP-A06-S300	6922794714304
5m	VAP-A06-S500	6922794714311
10m	VAP-A06-S1000	6922794714335
15m	VAP-A06-S1500	6922794714359

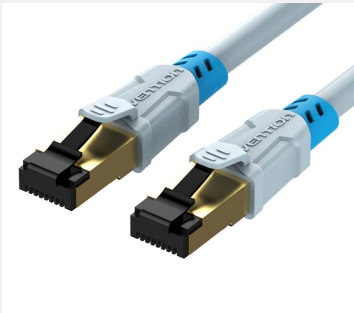

Package Contents

CAT6 SFTP Patch Cord Cable

Packaging Information

Packing Dimension	cm
Packing Weight	kg
Carton Dimension	48*29*30cm
Carton Qty	100pcs(0.75m,1m,1.5m),80pcs(2m),60pcs(3m), 50pcs(5m)
Carton Weight	5-6kgs(0.75m,1m,1.5m), 7-8kgs(2m-5m)
Package	PE Bag