


MHS-U-001

USB stereo headset, glossy black

MUSIC & MORE

- Clear and powerful sound
- Comfortable to wear
- Perfect for music, gaming and online chats
- Tested with MAC PC

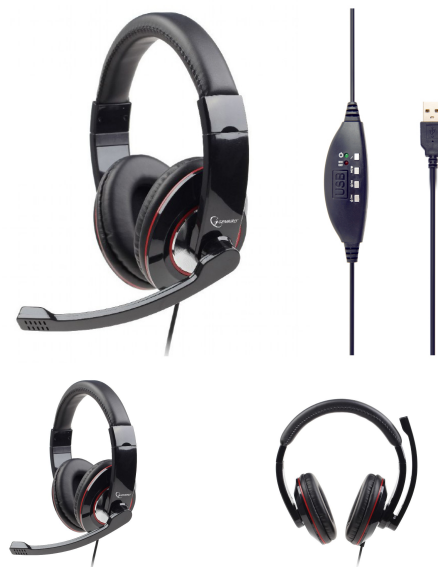

Features

- USB headset with rotating microphone boom
- Digital audio chipset for crystal clear sound
- Practical in-line control for volume, mute and microphone
- Large comfortable ear cushions
- Comfortable, adjustable headband

Specifications

Interface: USB 3.0/2.0/1.1 compatible
Sensitivity (at 1KHz) : 105 +/-3 dB
Impedance : 32 Ohm +/-15%
Speakers: 30 mm diameter, 16u mylar
Frequency response: 18 20000 Hz
Input power: 40 mW nominally, up to 100 mW max
Distortions: < 3 % at 1KHz 40mW
Microphone: condenser omni-directional; sensitivity:-58 ± 3 dB(0 dB=1V/uBar at 1KHz), -38dB (0 dB=1V/Pa at 1KHz)
Net weight: 0.2 kg

Packaging

Q'ty in crtn, pcs	20
Crtn volume, CUM	0.072
Crtn weight, kgs	7.7
Individual package size LxWxH:	190x75x210 mm
Carton size LxWxH:	400x400x450 mm
Country of origin	CN
Barcode	8716309077248
Customs code	8518300090

System requirements

Windows 2000/XP/Vista/7/8 or Chrome OS
A free USB port

Certificates

