



RM 14/24 VAC/DC KL.BZ.N.EN OUTPUT RELAY

IN: 24 VAC/DC - OUT: 250 VAC/DC / 2 A

- 1 relay; 4 NO/NC contacts
- 2 A
- 24 V DC
- Screw terminals

Link to Product

Illustration

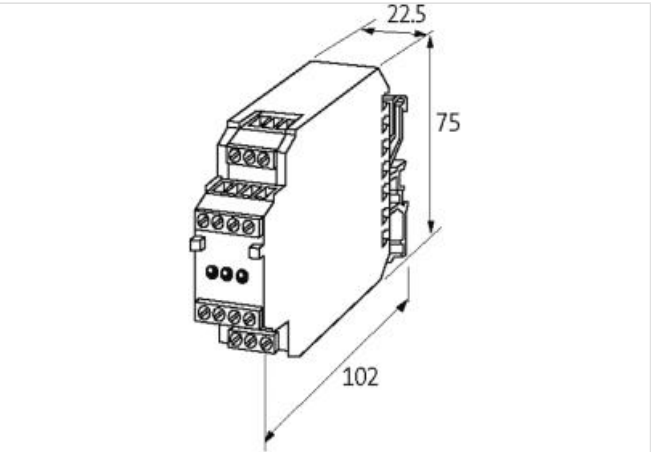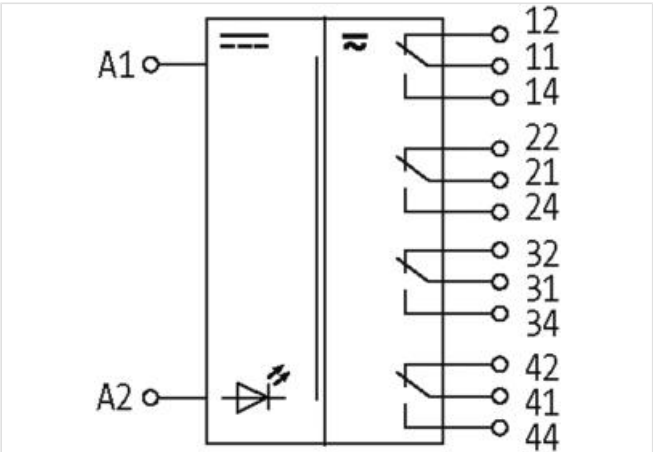

Product may differ from Image

General data	
Mounting method	DIN-rail mountable TH35 or G32 (EN 60715)
Temperature range	-20...+50 °C
Test isolation voltage	1.5 kV
Mech./ elect. life	50 000 000 switching cycles/load dependent
Dimensions HxWxD	75x22.5x102 mm
Output	
Min. load current	0.1 mA
Contact material	Ag Au
Energize/release/contact bounce time	10/20/2 ms
Switching voltage	max. 250 V AC/DC

Switching frequency	max. 0.1 Hz (with load)
---------------------	-------------------------

Power rating (voltage dependent)	max. 125 VA/60 W
----------------------------------	------------------

Switching current per output	max. 2 A
------------------------------	----------

Input

Connection voltage - current	24 V AC/DC (20.4...26.4 V AC/DC) - 20 mA
------------------------------	--

LED display	LED (red)
-------------	-----------

Utilization category

AC-15	1 A (24 V AC); 0.1 A (230 V AC)
-------	---------------------------------

AC-12	2 A (24 V AC); 0.5 A (230 V AC)
-------	---------------------------------

DC-13	0.8 A (24 V DC); 0.01 A (230 V DC)
-------	------------------------------------

Product article number of manufacturer	51410
--	-------