
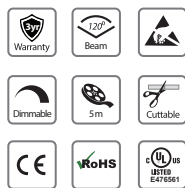


335 Series

335 60LED

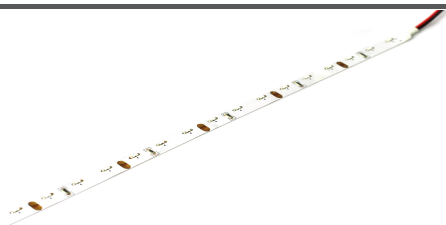

CRI Option

- 80+
- 90+

PCB Thickness

- 2oz
- 3oz
- 4oz - on request

PCB Color

- White
- Black
- Golden

Color Option


- 2700K
- 3000K
- 4000K
- 5000K
- 6000K
- Red
- Green
- Blue
- Yellow

Technical Data

Voltage	Code	Color	Watts	Lumen	Efficiency	Pitch	Width
12VDC	I60108-27	2700K	4.8	336	70	50mm	8mm
	I60108-30	3000K	4.8	345	72		8mm
	I60108-40	4000K	4.8	360	75		8mm
	I60108-50	5000K	4.8	360	75		8mm
	I60108-65	6500K	4.8	360	75		8mm
24VDC	I60208-27	2700K	4.8	336	70	100mm	8mm
	I60208-30	3000K	4.8	345	72		8mm
	I60208-40	4000K	4.8	360	75		8mm
	I60208-50	5000K	4.8	360	75		8mm
	I60208-65	6500K	4.8	360	75		8mm

The above measurements are based on IP20.
The above measurements can have a 10% tolerance.

Dimensions

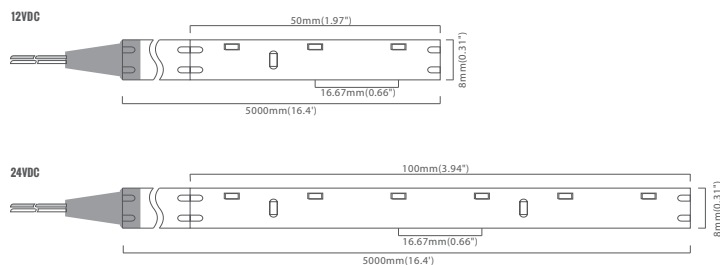

Main Features

- Ra 90+ for true color.
- 12V or 24V low voltage input for human safety.
- Ideal for office, residential, retail and industry lighting.

Available Waterproof Ways

IP Rating	20	54A	54B	65A	65B	67	68
Section							
Material	none	Silicone glue on surface	PU glue on surface	Inject with Heat Shrink tube	Inject with silicone tube	Silicone extrusion	Silicone extrusion

Accessory

More Options on P263



HH-1616



HH-1707D



HH-1707

Accessory

Connector



020101001



020101002



020101003