

Data Sheet | Item Number: 216-241


Ferrule; Sleeve for 0.5 mm² / 20 AWG; insulated; electro-tin plated; electrolytic copper; gastight crimped; acc. to DIN 46228, Part 4/09.90; white

<https://www.wago.com/216-241>



Color: white

Similar to illustration

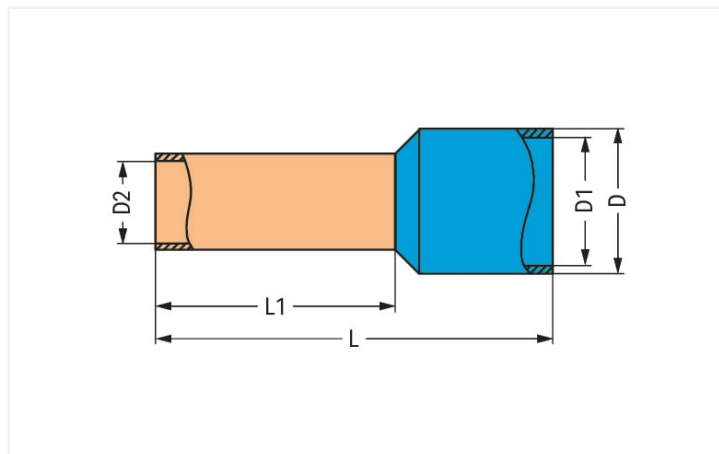

Dimensions in mm

Technical data

Main product function	Ferrule
Sleeve cross-section (AWG)	20 AWG
Sleeve for	0.5 mm ²

Connection data

Strip length	12 mm / 0.47 inches
--------------	---------------------

Physical data

Length	16 mm
Length 1	10 mm
Diameter	3.1 mm
Diameter 1	2.6 mm
Diameter 2	1 mm

Mechanical Data

Suitable	2001 – 2002 Series
----------	--------------------

Material Data

Color	white
Fire load	0.001 MJ
Weight	0.1 g



Commercial data		
PU (SPU)		1000 pcs
Packaging type		Box
Country of origin		DE
GTIN		4044918016315
Customs tariff number		85369010000

Downloads

Environmental Product Compliance

Compliance Search

Environmental Product Compliance 216-241

↓

Documentation				
Bid Text				
216-241	19.02.2019	xml	2.80 KB	↓
216-241	11.09.2017	doc	23.50 KB	↓

Installation Notes

