

Data Sheet | Item Number: 216-242


Ferrule; Sleeve for 0.75 mm² / 18 AWG; insulated; electro-tin plated; electrolytic copper; gastight crimped; acc. to DIN 46228, Part 4/09.90; gray

<https://www.wago.com/216-242>



Color:  gray

Similar to illustration

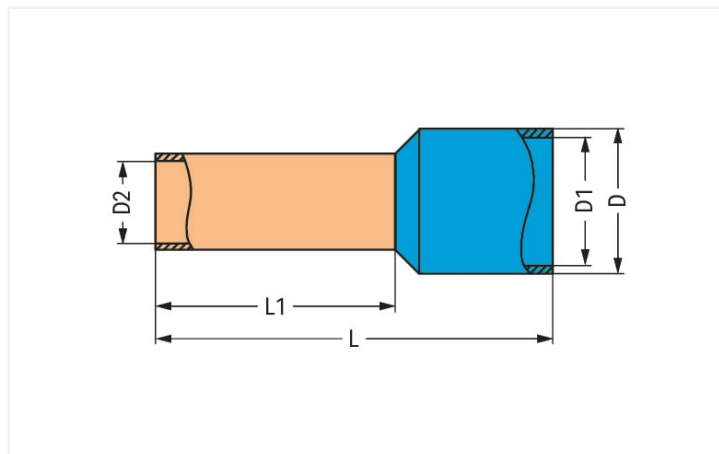

Dimensions in mm

Technical data

Main product function	Ferrule
Sleeve cross-section (AWG)	18 AWG
Sleeve for	0.75 mm ²

Connection data

Strip length	12 mm / 0.47 inches
--------------	---------------------

Physical data

Length	16 mm
Length 1	10 mm
Diameter	3.3 mm
Diameter 1	2.8 mm
Diameter 2	1.2 mm

Mechanical Data

Suitable	2001 – 2002 Series
----------	--------------------

Material Data

Color	gray
Fire load	0.002 MJ
Weight	0.1 g



Commercial data		
PU (SPU)		1000 pcs
Packaging type		Box
Country of origin		DE
GTIN		4044918016322
Customs tariff number		85369010000

Downloads

Environmental Product Compliance

Compliance Search	
Environmental Product Compliance 216-242	

Documentation

Bid Text			
216-242	19.02.2019	xml 2.80 KB	
216-242	11.09.2017	doc 23.50 KB	

Installation Notes

