 


Receptacle
KS-002 47 G
Item KS-00247G



ingun[®]
Partner for Future Technology

INGUN SELECTION



1:1

Receptacle

KS-002 47 G

Item KS-00247G



ingun[®]
Partner for Future Technology

General data

Product group	Receptacles (KS)
Series	KS-002
Sub-series	KS-002 press-in version
Type of receptacle connection	Wire-wrap
Press ring	Yes
Surface area	Gold
Collar diameter	1.78 mm [.070 in]
Collar height	6.1 mm [.240 in]
Knurl	No
Vacuum-tight	No
RoHS-compliant	Yes


Mounting hole

Mounting hole in CEM1	1.68 - 1.69 mm [.066 - .066 in]
Mounting hole in FR4	1.68 - 1.69 mm [.066 - .066 in]
Mounting hole with press ring in CEM1	1.70 - 1.75 mm [.066 - .068 in]
Mounting hole with press ring in FR4	1.70 - 1.75 mm [.066 - .068 in]

Mechanical data

Total length	33.5 mm [1.31 in]
Outer diameter	1.67 mm [.065 in]

INGUN SELECTION

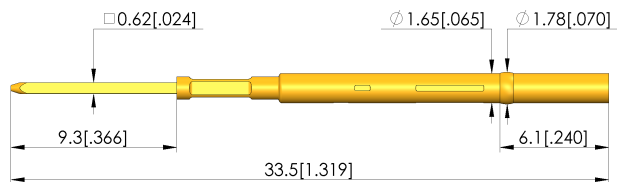

INGUN Prüfmittelbau GmbH

Max-Stromeyer-Straße 162
78467, Constance, Germany
Phone +49 7531 8105-0
Customer hotline +49 7531 8105-888
Fax +49 7531 8105-65
info@ingun.com



Prices and delivery times on request.
Technical changes reserved. 11/22 EN

Weitere Informationen zum Thema
Test probes



ingun.com