

Receptacle  
**KS-003 30 G**  
Item KS-00330G



**ingun®**  
Partner for Future Technology

**INGUN SELECTION**



1:1

# Receptacle

## KS-003 30 G

Item KS-00330G



**ingun**<sup>®</sup>  
Partner for Future Technology

### General data

|                               |                         |
|-------------------------------|-------------------------|
| Product group                 | Receptacles (KS)        |
| Series                        | KS-003                  |
| Sub-series                    | KS-003 press-in version |
| Type of receptacle connection | Solder                  |
| Press ring                    | Yes                     |
| Surface area                  | Gold                    |
| Collar diameter               | 2.49 mm [.098 in]       |
| Collar height                 | 7.6 mm [.299 in]        |
| Knurl                         | No                      |
| Vacuum-tight                  | No                      |
| RoHS-compliant                | Yes                     |


### Mounting hole

|                                       |                                 |
|---------------------------------------|---------------------------------|
| Mounting hole in CEM1                 | 2.33 - 2.34 mm [.091 - .092 in] |
| Mounting hole in FR4                  | 2.33 - 2.34 mm [.091 - .092 in] |
| Mounting hole with press ring in CEM1 | 2.39 - 2.44 mm [.094 - .096 in] |
| Mounting hole with press ring in FR4  | 2.39 - 2.44 mm [.094 - .096 in] |

### Mechanical data

|                |                   |
|----------------|-------------------|
| Total length   | 30.2 mm [1.18 in] |
| Outer diameter | 2.36 mm [.092 in] |

### INGUN SELECTION

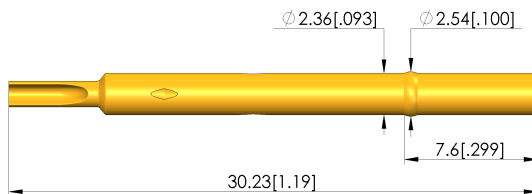

### INGUN Prüfmittelbau GmbH

Max-Stromeyer-Straße 162  
78467, Constance, Germany  
Phone +49 7531 8105-0  
Customer hotline +49 7531 8105-888  
Fax +49 7531 8105-65  
info@ingun.com



Prices and delivery times on request.  
Technical changes reserved. 11/22 EN

Weitere Informationen zum Thema  
**Test probes**



RECEPTACLES

ingun.com