


Receptacle
KS-004 30 G
Item KS-00430G



ingun[®]
Partner for Future Technology

INGUN SELECTION

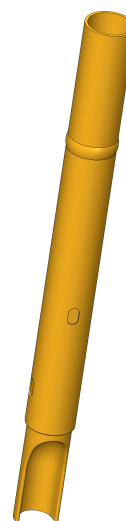

1:1

Receptacle

KS-004 30 G

Item KS-00430G



ingun[®]
Partner for Future Technology

General data

Product group	Receptacles (KS)
Series	KS-004
Sub-series	KS-004 press-in version
Type of receptacle connection	Solder
Press ring	Yes
Surface area	Gold
Collar diameter	2.8 mm [.110 in]
Collar height	7.6 mm [.299 in]
Knurl	No
Vacuum-tight	No
RoHS-compliant	Yes


Mounting hole

Mounting hole in CEM1	2.67 - 2.68 mm [.105 - .105 in]
Mounting hole in FR4	2.67 - 2.68 mm [.105 - .105 in]
Mounting hole with press ring in CEM1	2.72 - 2.77 mm [.107 - .109 in]
Mounting hole with press ring in FR4	2.72 - 2.77 mm [.107 - .109 in]

Mechanical data

Total length	30.5 mm [1.20 in]
Outer diameter	2.69 mm [.105 in]

INGUN SELECTION

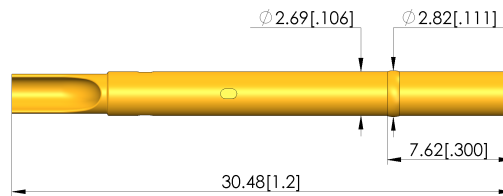

INGUN Prüfmittelbau GmbH

Max-Stromeyer-Straße 162
78467, Constance, Germany
Phone +49 7531 8105-0
Customer hotline +49 7531 8105-888
Fax +49 7531 8105-65
info@ingun.com



Prices and delivery times on request.
Technical changes reserved. 11/22 EN

Weitere Informationen zum Thema
Test probes



RECEPTACLES

ingun.com