

Receptacle A
KS-040 E08
Item KS-040E08



INGUN SELECTION



1:1

Receptacle A

KS-040 E08

Item KS-040E08




ingun[®]

Partner for Future Technology

General data

Product group	Receptacles (KS)
Series	KS-040
Sub-series	KS-040 press-in version
Type of receptacle connection	Plug / open
Press ring	Yes
Surface area	Gold
Collar diameter	0.82 mm [.032 in]
Collar height	7.9 mm [.311 in]
Knurl	No
Vacuum-tight	No
RoHS-compliant	Yes

INGUN SELECTION

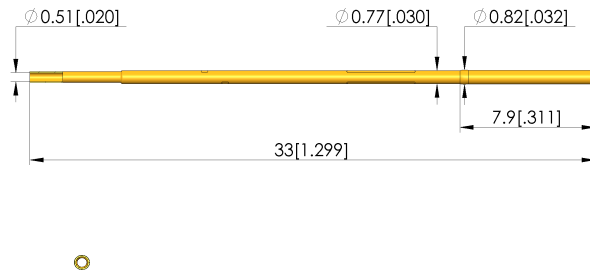

Mounting hole

Mounting hole in CEM1	0.79 - 0.80 mm [.031 - .031 in]
Mounting hole in FR4	0.79 - 0.80 mm [.031 - .031 in]

Mechanical data

Total length	33 mm [1.29 in]
Outer diameter	0.77 mm [.030 in]

INGUN Prüfmittelbau GmbH

Max-Stromeyer-Straße 162
78467, Constance, Germany
Phone +49 7531 8105-0
Customer hotline +49 7531 8105-888
Fax +49 7531 8105-65
info@ingun.com



Prices and delivery times on request.
Technical changes reserved. 11/22 EN

Weitere Informationen zum Thema
Test probes



RECEPTACLES