

Receptacle
KS-050 47 E08
Item KS-05047E08



INGUN SELECTION



Receptacle

KS-050 47 E08

Item KS-05047E08



ingun[®]
Partner for Future Technology

General data

Product group	Receptacles (KS)
Series	KS-050
Sub-series	KS-050 press-in version
Type of receptacle connection	Wire-wrap
Press ring	Yes
Surface area	Gold
Collar diameter	1.05 mm [.041 in]
Collar height	7.9 mm [.311 in]
Wire-wrap post length	8.7 mm [.342 in]
Knurl	No
Vacuum-tight	yes (< 1 ccm / min)
RoHS-compliant	Yes


Mounting hole

Mounting hole in CEM1	0.98 - 1.00 mm [.038 - .039 in]
Mounting hole in FR4	0.98 - 1.00 mm [.038 - .039 in]
Mounting hole with press ring in CEM1	0.98 - 1.00 mm [.038 - .039 in]
Mounting hole with press ring in FR4	0.98 - 1.00 mm [.038 - .039 in]

Mechanical data

Total length	49.3 mm [1.94 in]
Outer diameter	0.95 mm [.037 in]

INGUN SELECTION

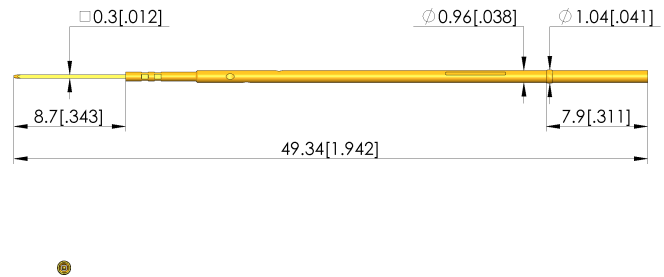

INGUN Prüfmittelbau GmbH

Max-Stromeyer-Straße 162
78467, Constance, Germany
Phone +49 7531 8105-0
Customer hotline +49 7531 8105-888
Fax +49 7531 8105-65
info@ingun.com



Prices and delivery times on request.
Technical changes reserved. 11/22 EN

Weitere Informationen zum Thema
Test probes



RECEPTACLES

ingun.com