

Receptacle
KS-069 30 G
Item KS-06930G



ingun[®]
Partner for Future Technology

INGUN SELECTION



1:1

Receptacle

KS-069 30 G

Item KS-06930G



ingun[®]
Partner for Future Technology

General data

Product group	Receptacles (KS)
Series	KS-069
Sub-series	KS-069 press-in version
Type of receptacle connection	Solder
Press ring	Yes
Surface area	Gold
Collar diameter	0.94 mm [.037 in]
Collar height	2.54 mm [.1 in]
Knurl	No
Vacuum-tight	No
RoHS-compliant	Yes


Mounting hole

Mounting hole in CEM1	0.86 - 0.92 mm [.033 - .036 in]
Mounting hole in FR4	0.86 - 0.92 mm [.033 - .036 in]
Mounting hole with press ring in CEM1	0.86 - 0.92 mm [.033 - .036 in]
Mounting hole with press ring in FR4	0.86 - 0.92 mm [.033 - .036 in]

Mechanical data

Total length	17.5 mm [.688 in]
Outer diameter	0.86 mm [.033 in]

INGUN SELECTION

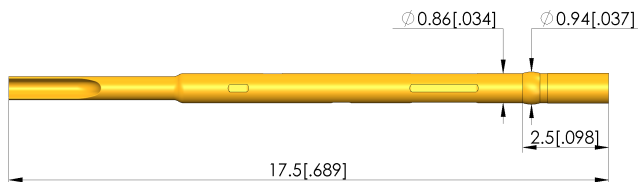

INGUN Prüfmittelbau GmbH

Max-Stromeyer-Straße 162
78467, Constance, Germany
Phone +49 7531 8105-0
Customer hotline +49 7531 8105-888
Fax +49 7531 8105-65
info@ingun.com



Prices and delivery times on request.
Technical changes reserved. 11/22 EN

Weitere Informationen zum Thema
Test probes



RECEPTACLES

ingun.com