

KS for GKS-100: inst. height 10.5mm

KS-100 30 05

 
Item KS-1003005



ingun®

Partner for Future Technology

INGUN SELECTION



1:1

KS for GKS-100: inst. height 10.5mm

KS-100 30 05

Item KS-1003005



GO TO PRODUCT

ingun[®]

Partner for Future Technology

General data

Product group	Receptacles (KS)
Series	KS-100
Sub-series	KS-100 press-in version
Type of receptacle connection	Solder
Press ring	No
Surface area	Gold
Collar diameter	1.8 mm [.070 in]
Collar height	0.2 mm [.007 in]
Knurl	No
Vacuum-tight	No
RoHS-compliant	Yes


Mounting hole

Mounting hole in CEM1	1.68 - 1.69 mm [.066 - .066 in]
Mounting hole in FR4	1.69 - 1.70 mm [.066 - .066 in]

Mechanical data

Total length	27.7 mm [1.09 in]
Outer diameter	1.67 mm [.065 in]

INGUN SELECTION

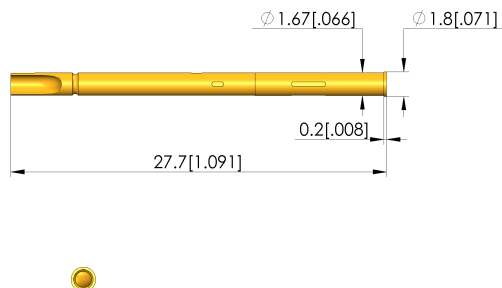

INGUN Prüfmittelbau GmbH

Max-Stromeyer-Straße 162
78467, Constance, Germany
Phone +49 7531 8105-0
Customer hotline +49 7531 8105-888
Fax +49 7531 8105-65
info@ingun.com



Prices and delivery times on request.
Technical changes reserved. 11/22 EN

Weitere Informationen zum Thema
Test probes



RECEPTACLES

ingun.com