 


Receptacle
KS-100 47 25
Item KS-1004725



ingun[®]
Partner for Future Technology

INGUN SELECTION



1:1

Receptacle

KS-100 47 25

Item KS-1004725



ingun[®]

Partner for Future Technology

General data

Product group	Receptacles (KS)
Series	KS-100
Sub-series	KS-100 press-in version
Type of receptacle connection	Wire-wrap
Press ring	No
Surface area	Gold
Collar diameter	1.8 mm [.070 in]
Collar height	2.5 mm [.098 in]
Wire-wrap post length	9.3 mm [.366 in]
Knurl	No
Vacuum-tight	yes (< 1 ccm / min)
RoHS-compliant	Yes


Mounting hole

Mounting hole in CEM1	1.68 - 1.69 mm [.066 - .066 in]
Mounting hole in FR4	1.69 - 1.70 mm [.066 - .066 in]

Mechanical data

Total length	36.8 mm [1.44 in]
Outer diameter	1.67 mm [.065 in]

INGUN SELECTION

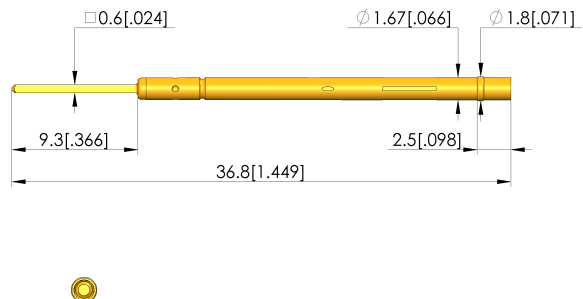

INGUN Prüfmittelbau GmbH

Max-Stromeyer-Straße 162
78467, Constance, Germany
Phone +49 7531 8105-0
Customer hotline +49 7531 8105-888
Fax +49 7531 8105-65
info@ingun.com



Prices and delivery times on request.
Technical changes reserved. 11/22 EN

Weitere Informationen zum Thema
Test probes



RECEPTACLES

ingun.com