

Receptacle A

KS-101 47

Item KS-10147



ingun[®]

Partner for Future Technology

INGUN SELECTION



1:1

RECEPTACLES

Receptacle A

KS-101 47

Item KS-10147



ingun[®]

Partner for Future Technology

General data

Product group	Receptacles (KS)
Series	KS-101
Sub-series	KS-101 press-in version
Type of receptacle connection	Wire-wrap
Press ring	No
Surface area	Gold
Collar diameter	1.42 mm [.055 in]
Collar height	0.2 mm [.007 in]
Wire-wrap post length	6 mm [.236 in]
Knurl	No
Vacuum-tight	yes (< 1 ccm / min)
RoHS-compliant	Yes


Mounting hole

Mounting hole in CEM1	1.31 - 1.32 mm [.051 - .051 in]
Mounting hole in FR4	1.31 - 1.32 mm [.051 - .051 in]

Mechanical data

Total length	24 mm [.944 in]
Outer diameter	1.32 mm [.051 in]

INGUN SELECTION

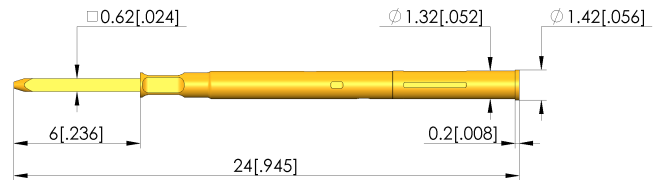

INGUN Prüfmittelbau GmbH

Max-Stromeyer-Straße 162
78467, Constance, Germany
Phone +49 7531 8105-0
Customer hotline +49 7531 8105-888
Fax +49 7531 8105-65
info@ingun.com



Prices and delivery times on request.
Technical changes reserved. 11/22 EN

Weitere Informationen zum Thema
Test probes



RECEPTACLES

ingun.com