 


Receptacle
KS-112 30
Item KS-11230



ingun[®]
Partner for Future Technology

INGUN SELECTION



1:1

Receptacle

KS-112 30

Item KS-11230



GO TO PRODUCT

ingun[®]

Partner for Future Technology

General data

Product group	Receptacles (KS)
Series	KS-112
Sub-series	KS-112 press-in version
Type of receptacle connection	Solder
Press ring	No
Surface area	Gold
Collar diameter	2.2 mm [.086 in]
Collar height	0.2 mm [.007 in]
Knurl	No
Vacuum-tight	No
RoHS-compliant	Yes


Mounting hole

Mounting hole in CEM1	1.98 - 2.00 mm [.077 - .078 in]
Mounting hole in FR4	1.99 - 2.01 mm [.078 - .079 in]

Mechanical data

Total length	30 mm [1.18 in]
Outer diameter	2 mm [.078 in]

INGUN SELECTION

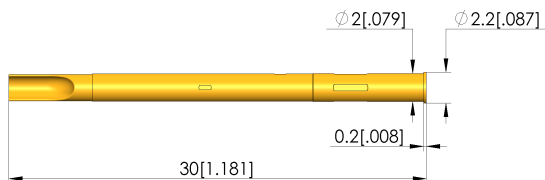

INGUN Prüfmittelbau GmbH

Max-Stromeyer-Straße 162
78467, Constance, Germany
Phone +49 7531 8105-0
Customer hotline +49 7531 8105-888
Fax +49 7531 8105-65
info@ingun.com



Prices and delivery times on request.
Technical changes reserved. 11/22 EN

Weitere Informationen zum Thema
Test probes



RECEPTACLES