

Receptacle

KS-112 47

 
Item KS-11247



ingun®

Partner for Future Technology

INGUN SELECTION



1:1

Receptacle

KS-112 47

Item KS-11247




ingun[®]

Partner for Future Technology

General data

Product group	Receptacles (KS)
Series	KS-112
Sub-series	KS-112 press-in version
Type of receptacle connection	Wire-wrap
Press ring	No
Surface area	Gold
Collar diameter	2.2 mm [.086 in]
Collar height	0.2 mm [.007 in]
Wire-wrap post length	8.2 mm [.322 in]
Knurl	No
Vacuum-tight	yes (< 1 ccm / min)
RoHS-compliant	Yes

INGUN SELECTION

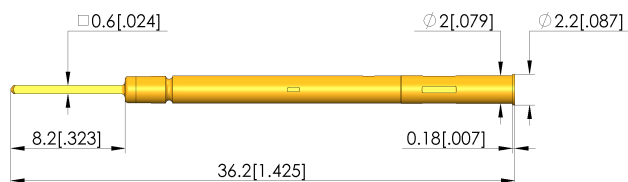

Mounting hole

Mounting hole in CEM1	1.98 - 2.00 mm [.077 - .078 in]
Mounting hole in FR4	1.99 - 2.01 mm [.078 - .079 in]

Mechanical data

Total length	36.2 mm [1.42 in]
Outer diameter	2 mm [.078 in]

INGUN Prüfmittelbau GmbH

Max-Stromeyer-Straße 162
78467, Constance, Germany
Phone +49 7531 8105-0
Customer hotline +49 7531 8105-888
Fax +49 7531 8105-65
info@ingun.com



Prices and delivery times on request.
Technical changes reserved. 11/22 EN

Weitere Informationen zum Thema
Test probes



RECEPTACLES

ingun.com