

Receptacle

KS-113 46

 
Item KS-11346



ingun®

Partner for Future Technology

INGUN SELECTION



1:1

Receptacle

KS-113 46

Item KS-11346



GO TO PRODUCT


ingun[®]

Partner for Future Technology

General data

Product group	Receptacles (KS)
Series	KS-113
Sub-series	KS-113 press-in version
Type of receptacle connection	Wire-wrap
Press ring	No
Surface area	Gold
Collar diameter	3.2 mm [.125 in]
Collar height	0.2 mm [.007 in]
Wire-wrap post length	20 mm [.787 in]
Knurl	No
Vacuum-tight	No
RoHS-compliant	Yes

INGUN SELECTION

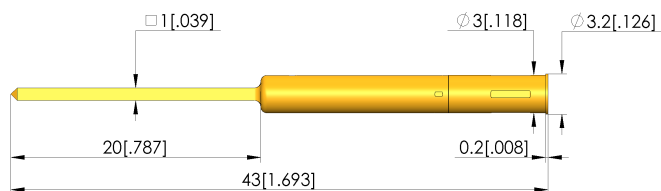

Mounting hole

Mounting hole in CEM1	2.98 - 2.99 mm [.117 - .117 in]
Mounting hole in FR4	2.98 - 2.99 mm [.117 - .117 in]

Mechanical data

Total length	43 mm [1.69 in]
Outer diameter	3 mm [.118 in]

INGUN Prüfmittelbau GmbH

Max-Stromeyer-Straße 162
78467, Constance, Germany
Phone +49 7531 8105-0
Customer hotline +49 7531 8105-888
Fax +49 7531 8105-65
info@ingun.com



Prices and delivery times on request.
Technical changes reserved. 11/22 EN

Weitere Informationen zum Thema
Test probes



RECEPTACLES

ingun.com