

KS 0.6 μm Au (BG)

KS-550 E08

 
Item KS-550E08



ingun[®]

Partner for Future Technology

INGUN SELECTION



1:1

RECEPTACLES

KS 0.6 μm Au (BG)

KS-550 E08

Item KS-550E08



ingun[®]

Partner for Future Technology

General data

Product group	Receptacles (KS)
Series	KS-550
Sub-series	KS-550 press-in version
Type of receptacle connection	Plug / open
Press ring	Yes
Surface area	Gold
Collar diameter	1.05 mm [.041 in]
Collar height	7.6 mm [.299 in]
Knurl	No
Vacuum-tight	No
RoHS-compliant	Yes


Mounting hole

Mounting hole in CEM1	0.96 - 0.98 mm [.037 - .038 in]
Mounting hole in FR4	0.97 - 0.99 mm [.038 - .038 in]
Mounting hole with press ring in CEM1	0.96 - 0.98 mm [.037 - .038 in]
Mounting hole with press ring in FR4	0.97 - 0.99 mm [.038 - .038 in]

Mechanical data

Total length	31.6 mm [1.24 in]
Outer diameter	0.95 mm [.037 in]

INGUN SELECTION

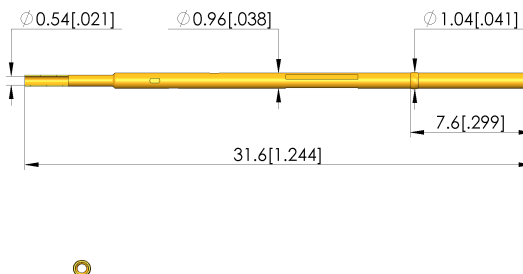

INGUN Prüfmittelbau GmbH

Max-Stromeyer-Straße 162
78467, Constance, Germany
Phone +49 7531 8105-0
Customer hotline +49 7531 8105-888
Fax +49 7531 8105-65
info@ingun.com



Prices and delivery times on request.
Technical changes reserved. 11/22 EN

Weitere Informationen zum Thema
Test probes



RECEPTACLES