

D-Sub

TECHNICAL SPECIFICATIONS


Materials:

Unshielded Hood: UL-recognised plastic material
 Colour: Black

Shielded Hood: UL-recognised plastic material
 Plating: Nickel over Copper

Operating Temperature: -30°C to +110°C

Jackscrews: UNC 4-40 (Standard)

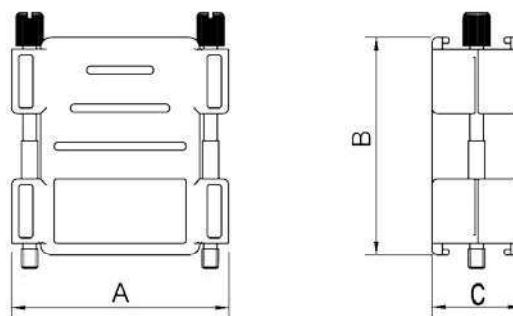

Size DA	Dim A	Dim B	Dim C
9-way	31,6	40,0	16,4
15-way	39,9	40,0	16,4
25-way	53,6	40,0	16,4

Ordering information:

Size:	P/N - Kitted:	Product Code:
9-way	1511-0100-01	DPAK-P-09-K
15-way	1511-0100-02	DPAK-P-15-K
25-way	1511-0100-03	DPAK-P-25-K



Encitech Connectors AB
 Rörkullsvägen 4
 SE-302 41 HALMSTAD, Sweden

Tel: +46-(0)35-15 13 90
 e-mail: connectors@encitech.com

www.encitech.com