


Locking and sealing rings

BN 1081

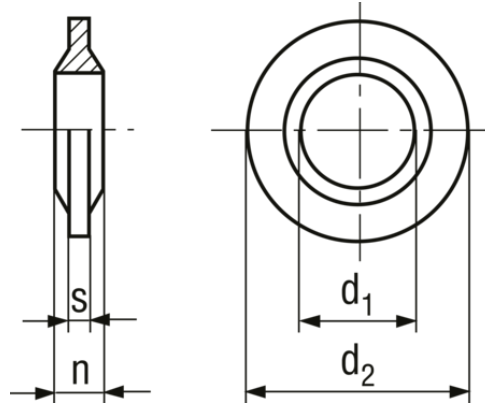

Product description

- Operating temperature range: -60 °C... +80 °C

Material

Polyamide

Material execution

PA

Color

natural

Article no.	for thread	Ww	d1	d2	n	s
1405942	M3	1/8"	3,1	7	1,4	0,7
1405950	M4	5/32"	4,1	9	2,8	1,25
1405969	M5	3/16"	5,1	10,4	3,5	1,4
1405977	M6	-	6,1	12	4	1,6
1405985	M6a	-	6,4	10,7	3,7	1
1405993	M8	5/16"	8,1	15,8	4,6	2,1
1406000	M10	3/8"	10	19,6	5,3	2,1
1406019	M12	7/16"	12	22	5,8	2,3
1406035	M16	5/8"	16,2	29,4	6,2	2,6
1406043	M18	-	18,1	31,5	6,9	2,7
1406078	M20	-	20,2	35,5	6,9	2,8