

DMX 5050 RGBW flex led strip 84LEDs/m



◆ Product Description:

SMD5050 RGBW 4 in 1 LED chip, 84LEDs/m

DMX control, every 7LEDs/pixel(4CH)

Input voltage is DC24V

Flex PCB and PCB color is white

1+2 Ounce copper, 12mm wide


Standard 5M/roll, length can be customized



◆ Product Datasheet

Product Number	S012084CC4DC0	Luminance/M	R:720 G:1635 B:470 W:2790lm
Operating Voltage	DC24V	Ra	/
Power/M	23W	Beam Angle	120°
SMD Type	SMD 5050	Size (mm)	5000 * 12mm
LED Qty/M	84	IP Rate	IP20/IP65
Color	RGBW:3000K/4000K/6000K	Operation Temperature	- 25 ~ 60 °C
Pixel/M	12	Material	FPC
Control	DMX/TM512AC	Cutting Length	83.33mm
Wavelength	R:620-625 G:520-525 B:460-465nm	Net Weight/Roll	0.18KG


◆ Outline Dimension (unit: mm)

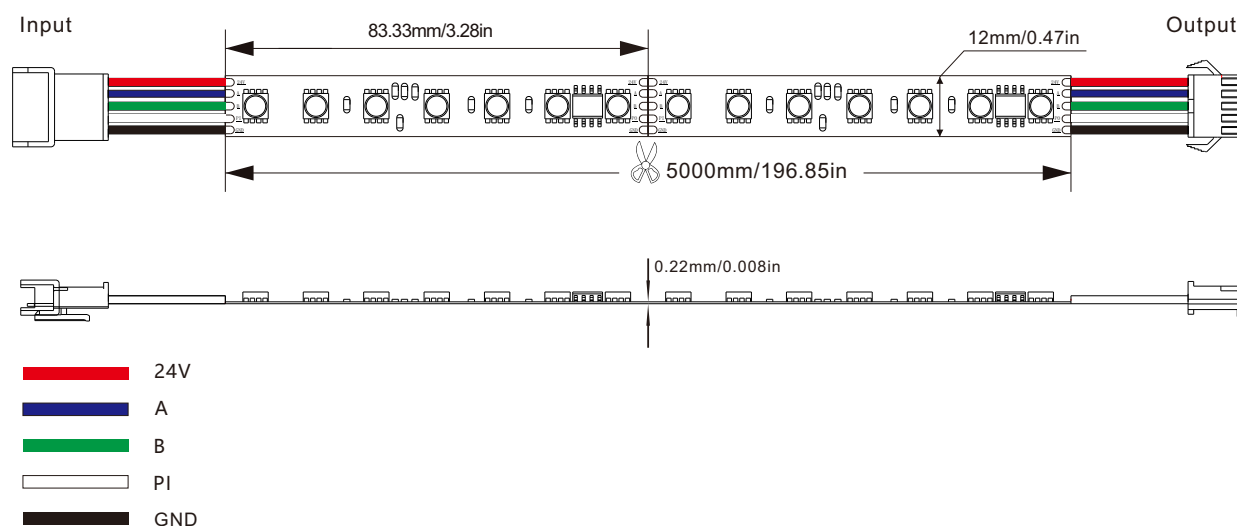


Order number

DC24V	RGBW+3000K	White PCB	IP20	S012084CC4DA0/C1
DC24V	RGBW+4000K	White PCB	IP20	S012084CC4DA0/C2
DC24V	RGBW+6000K	White PCB	IP20	S012084CC4DA0/C3
DC24V	RGBW+3000K	White PCB	IP65	S012084CC4DA0/C4
DC24V	RGBW+4000K	White PCB	IP65	S012084CC4DA0/C5
DC24V	RGBW+6000K	White PCB	IP65	S012084CC4DA0/C6

Wiring diagram

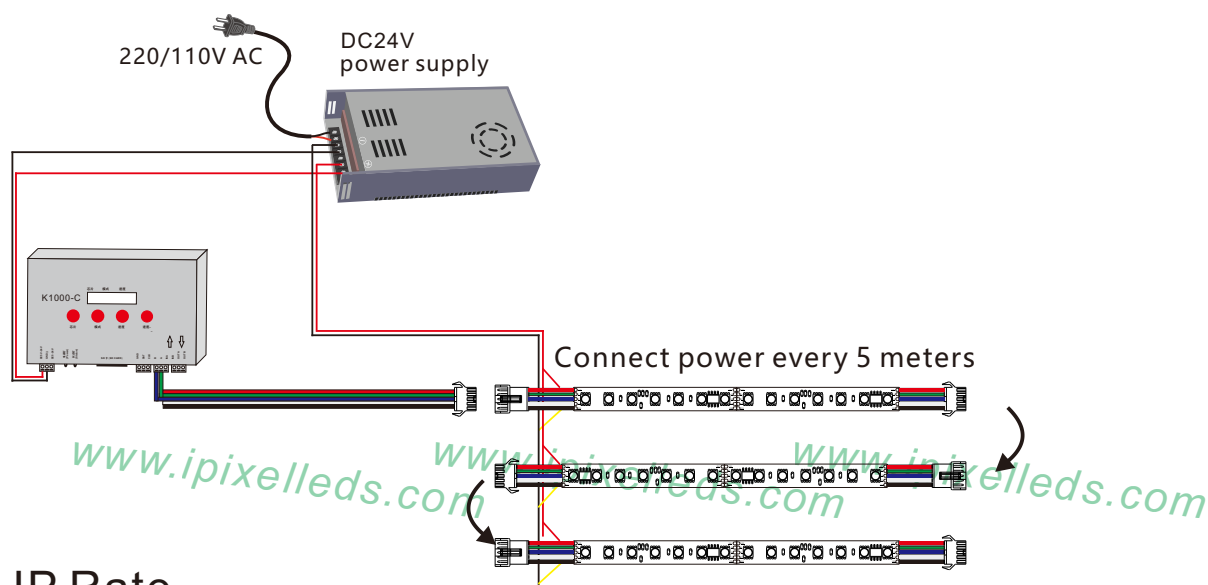

Strip IP Rate

 

Accessories



Screw




Silicone clip



End cap

Schematic diagram of maximum bending prevention

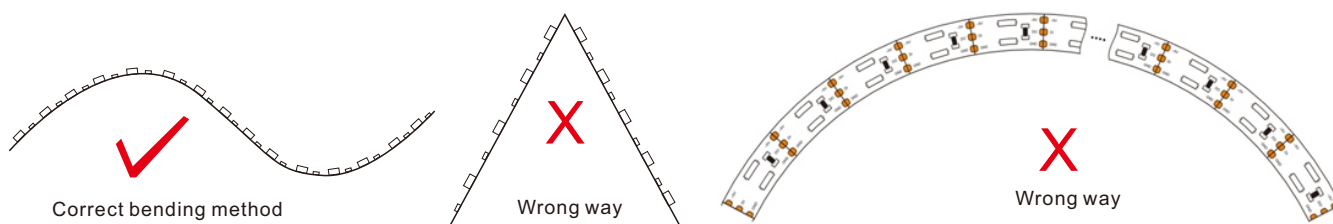

Note: The parameters are subject to change without notice!