





White DC Power Cable 0.5m long
PLUG 0.7x2.35 mm - straight
flexible, multiwire conductors,
stranded of bare copper wires
coaxial **1mm²**

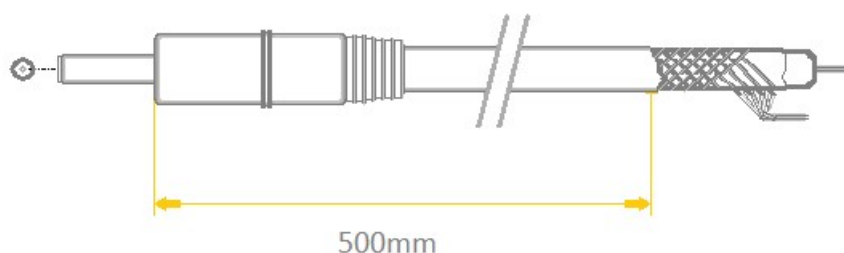

500mm

Model	P07-TT-C100-050WH
DC Plug (output)	0.7x2.35mm, straight (round plug, outer diameter 2.35mm, inner diameter 0.7mm)
DC Socket (input)	tinned terminals
Construction	flexible, multiwire conductors, stranded of bare annealed copper wires - coaxial
Cable cross section	3.95mm
Wire diameter	1.00 mm²
Nominal voltage	0-150V
Rated current	2A
Length	50cm
Jacket	PVC
Color	White
Inner conductor	Cu
Insulation resistance	>100MΩ @ 500VDC
Insulation thickness	0.3mm
Allowable operation temperature	-20°C to 70°C
Maximum wire resistance	18.0 Ω/km @ 20°C

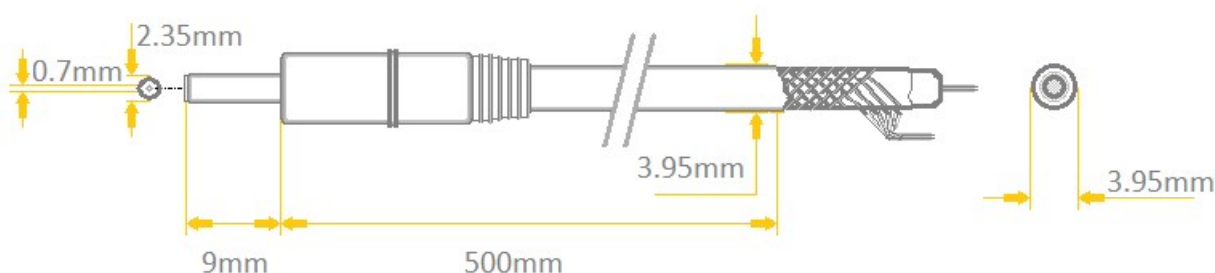

Marking System				model:		P07-TT-C100-050WH				
1	2	3	4	5	6	7	8			
P	07	-	T	T	-	C	100	-	050	WH
1	Input / Output (side 1)				P - straight plug A - angled plug S - socket					
2	Plug / Socket dimensions (side 1)				07 - 0.7mm / 2.35mm 13 - 1.3mm / 3.5mm 40 - 1.7mm x 4.0mm 48 - 1.7mm x 4.8mm 55 - 1.7mm / 5.5mm 21 - 2.1mm / 5.5mm 25 - 2.5mm x 5.5mm					
3	Input / Output (side 2)				P - straight plug A - angled plug S - socket					
4	Plug / Socket dimensions (side 2)				T - tinned terminals 07 - 0.7mm / 2.35mm 13 - 1.3mm / 3.5mm 40 - 1.7mm x 4.0mm 48 - 1.7mm x 4.8mm 55 - 1.7mm / 5.5mm 21 - 2.1mm / 5.5mm 25 - 2.5mm x 5.5mm					
5	cable type				C- YTLYek (coaxial) T- TLYP					
6	wire diameter				035 - 0.35mm ² 050 - 0.5mm ² 075 - 0.75mm ² 100 - 1.0mm ²					
7	length				050 - 500mm 150 - 1500mm					
8	color				BK - black WH - white TR - transparent					