





DC Power Cable 1.5m long
PLUG 2.1x5.5 mm - straight
 flexible, multiwire conductors,
 stranded of bare copper wires
2x0.50mm²

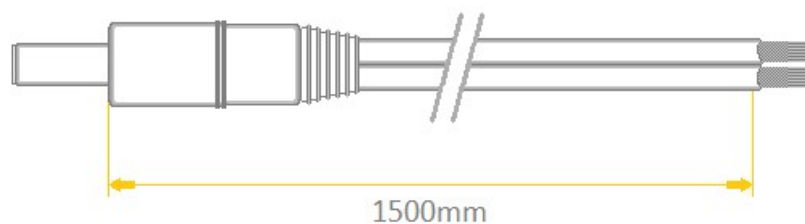

Model	P21-TT-T050-150BK
DC Plug (output)	2.1x5.5mm, straight (round plug, outer diameter 5.5mm, inner diameter 2.1mm)
DC Socket (input)	tinned terminals
Construction	flexible, multiwire conductors, stranded of bare annealed copper wires
Cable cross section	1.7 x 3.6mm
Wire diameter	2x0.5mm²
Nominal voltage	0-100V
Rated current	1.5A
Length	150cm
Jacket	PVC
Color	Black
Inner conductor	Cu
Insulation resistance	>100MΩ @ 500VDC
Insulation thickness	0.4mm
Allowable operation temperature	-20°C to 70°C
Maximum wire resistance	39 Ω/km @ 20°C

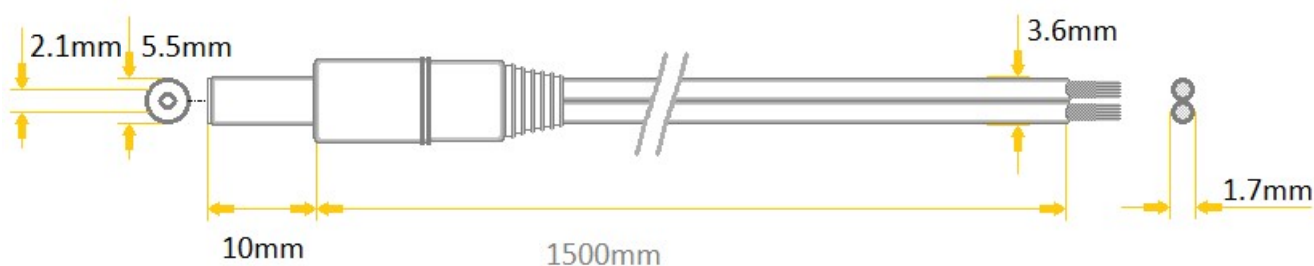

Marking System

model:

P21-TT-T050-150BK

1		2		3		4		5		6		7		8	
P	21	-	T	T	-	T	050	-	150	BK					

1	Input / Output (side 1)	P - straight plug A - angled plug S - socket
2	Plug / Socket dimensions (side 1)	07 - 0.7mm / 2.35mm 13 - 1.3mm / 3.5mm 40 - 1.7mm / 4.0mm 48 - 1.7mm / 4.8mm 55 - 1.7mm / 5.5mm 21 - 2.1mm / 5.5mm 25 - 2.5mm / 5.5mm
3	Input / Output (side 2)	P - straight plug A - angled plug S - socket
4	Plug / Socket dimensions (side 2)	T - tinned terminals 07 - 0.7mm / 2.35mm 13 - 1.3mm / 3.5mm 40 - 1.7mm / 4.0mm 48 - 1.7mm / 4.8mm 55 - 1.7mm / 5.5mm 21 - 2.1mm / 5.5mm 25 - 2.5mm / 5.5mm
5	cable type	C- YTLYek (coaxial) T- TLYP O- YTLY
6	wire diameter	035 - 0.35mm² 050 - 0.5mm² 075 - 0.75mm² 100 - 1.0mm²
7	length	050 - 500mm 150 - 1500mm
8	color	BK - black WH - white TR - transparent