



www.jbctools.com

INSTRUCTION MANUAL



PH217 / PH224

Kapton Tape /
ESD Kapton Tape

This manual corresponds to the following references:

PH217 - *Kapton Tape*

PH224 - *ESD Kapton Tape*

The following items are included:

Packing List




Kapton Tape or ESD Kapton Tape 1 unit
according to purchased reference



Manual 1 unit
Ref. 0029006

Features

The Kapton Tape allows to fix the thermocouples on the PCB.

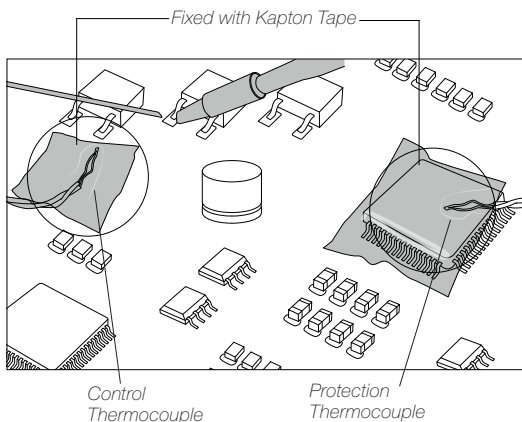

PH217 Kapton Tape

Adhesive tape with silicone resin, high heat resistance and excellent solvent resistance.

PH217 is not an ESD tape. Don't forget to work with an ionizer.

PH224 ESD Kapton Tape

Polyimide film coated with a special surface conductive adhesive. Leaves no adhesive residue on printed circuit boards after removal.

Specifications

PH217

Kapton Tape

Ref.: PH217

- Heat Resistance Short Term / Long Term: 290°C / 230°C; 554°F / 446°F

PH224

ESD Kapton Tape

Ref.: PH224

- Heat Resistance Short Term: 300°C / 572°F

For both tape types:

- Tape Width / Length:	12 mm / 33 mm; 0.47 in / 1.30 in
- Net Weight:	43.7 g / 0.10 lb
- Package Dimensions / Weight:	155 x 85 x 55 mm / 68.9 g
(L x W x H)	6.10 x 3.35 x 2.17 / 0.15 lb

Complies with CE standards

JBC

Warranty

JBC's 2 year warranty covers this equipment against all manufacturing defects, including the replacement of defective parts and labour.

Warranty does not cover product wear or misuse.

In order for the warranty to be valid, equipment must be returned, postage paid, to the dealer where it was purchased.



This product should not be thrown in the garbage.

In accordance with the European directive 2012/19/EU, electronic equipment at the end of its life must be collected and returned to an authorized recycling facility.



www.jbctools.com

0029006-130522