


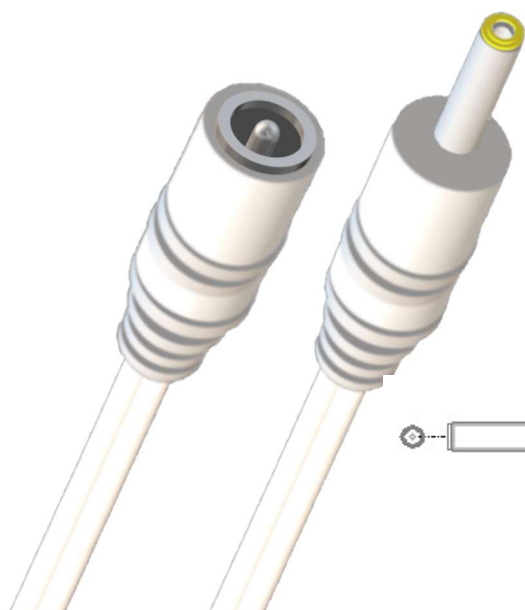


White DC Power Cable 0.5m long


Plug 0.7x2.35 mm – straight

Socket 2.1x5.5 mm

flexible, multiwire conductors,
stranded of bare copper wires
coaxial **0.5mm²**

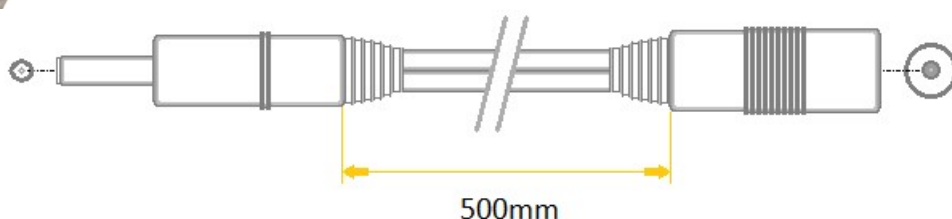

Model	P07-C21-T050-050WH
DC Plug (output)	0.7x2.35mm, straight (round plug, outer diameter 2.35mm, inner diameter 0.7mm)
DC Socket (input)	2.1x5.5mm, straight (round socket, outer diameter 2.1mm, inner diameter 5.5mm)
Construction	flexible, multiwire conductors, stranded of bare annealed copper wires
Cable cross section	1.7 x 3.6mm
Wire diameter	2x0.5mm²
Nominal voltage	0-100V
Rated current	1.5A
Length	50cm
Jacket	PVC
Color	White
Inner conductor	Cu
Insulation resistance	>100MΩ @ 500VDC
Insulation thickness	0.4mm
Allowable operation temperature	-20°C to 70°C
Maximum wire resistance	39.0 Ω/km @ 20°C

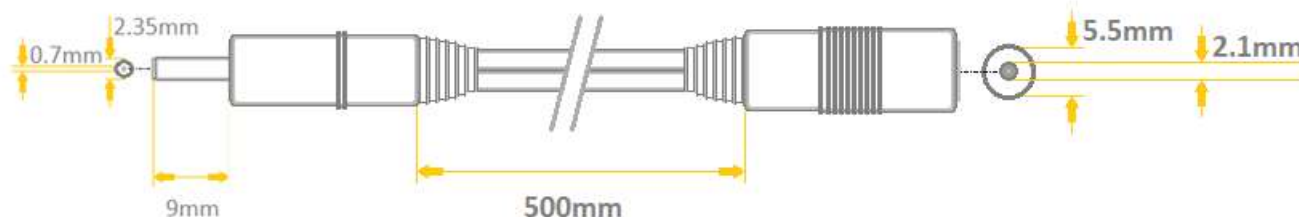

Marking System				model:		P07-C21-T050-050WH				
1	2	3	4	5	6	7	8			
P	07	-	C	21	-	T	050	-	050	WH
1	Input / Output (side 1)				P - straight plug A - angled plug C - socket					
2	Plug / Socket dimensions (side 1)				07 - 0.7mm / 2.35mm 13 - 1.3mm / 3.5mm 40 - 1.7mm x 4.0mm 48 - 1.7mm x 4.8mm 55 - 1.7mm / 5.5mm 21 - 2.1mm / 5.5mm 25 - 2.5mm x 5.5mm					
3	Input / Output (side 2)				P - straight plug A - angled plug C - socket					
4	Plug / Socket dimensions (side 2)				T - tinned terminals 07 - 0.7mm / 2.35mm 13 - 1.3mm / 3.5mm 40 - 1.7mm x 4.0mm 48 - 1.7mm x 4.8mm 55 - 1.7mm / 5.5mm 21 - 2.1mm / 5.5mm 25 - 2.5mm x 5.5mm					
5	cable type				C - YTLYek (coaxial) T - TLYP					
6	wire diameter				035 - 0.35mm ² 050 - 0.5mm ² 075 - 0.75mm ² 100 - 1.0mm ²					
7	length				050 - 500mm 150 - 1500mm					
8	color				BK - black WH - white TR - transparent					