


PURE SINE VOLTAGE INVERTER IPS-3000S


24 VDC / 230VAC 3000W / 1500W

	Input voltage: 22VDC ÷ 30VDC Output voltage: 230VAC Surge power: 3000VA Rated power: 1500VA Output wave form: Pure sine wave Motor soft start: YES Overload protection: YES Shortcut protection: YES Thermal protection: YES Overvoltage protection: 30VDC Battery deep discharge protection (AC output off): 21VDC Operating temperature: 0 ~ +40°C Efficiency: > 92% Cooling: Active Terminals: M8 230V socket: 2 pcs Case: Aluminium Protection: IP21 Dimensions: 370x230x108 [mm] Weight [kg]: 5.33kg Product code: 5903332566167
--	---


Inverter description

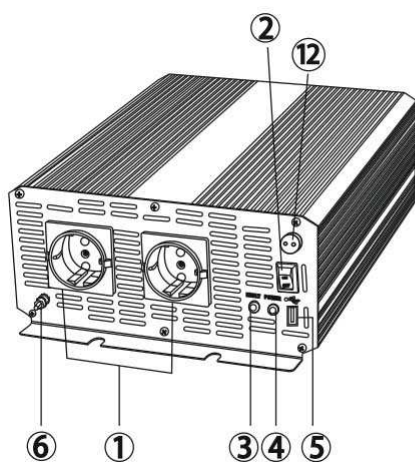

- 1 – 230V socket
- 2 – main switch
- 3 – indicator (fault)
- 4 – indicator (power on)
- 5 – USB charging port
- 6 – grounding
- 12 – remote control connector

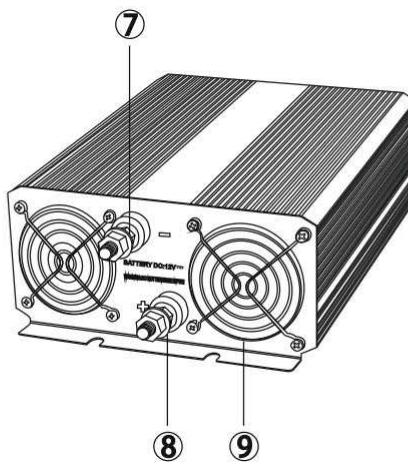

- 7 – 24V negative terminal
- 8 – 24V positive terminal
- 9 – fan

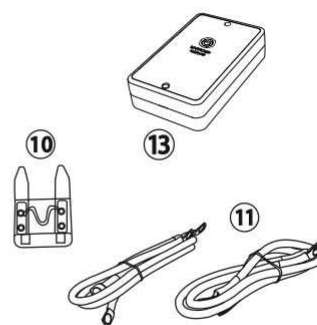

- 10 – fuse
- 11 – 24V power cables
- 13 – remote control