


PURE SINE VOLTAGE INVERTER IPS-4000S

12 VDC / 230 VAC 4000W / 2000W




Input voltage:	11VDC ÷ 15VDC
Output voltage:	230VAC
Surge power:	4000VA
Rated power:	2000VA
Output wave form:	Pure sine wave
Motor soft start:	YES
Overload protection:	YES
Shortcut protection:	YES
Thermal protection:	YES
Overvoltage protection:	15VDC
Battery deep discharge protection (AC output off):	10.5VDC
Operating temperature:	0 ~ +40°C
Efficiency:	> 92%
Cooling:	Active
Terminals:	M10
230V socket:	2 pcs
Case:	Aluminium
Protection:	IP21
Dimensions:	370x230x108 [mm]
Weight [kg]:	5.33kg
Product code:	5903332566105

Inverter description

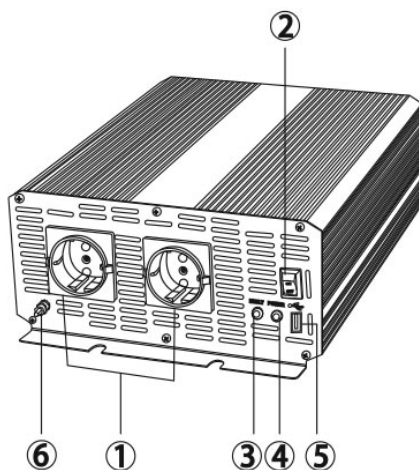

- 1 – 230V socket
- 2 – main switch
- 3 – indicator (fault)
- 4 – indicator (power on)
- 5 – USB charging port
- 6 – grounding

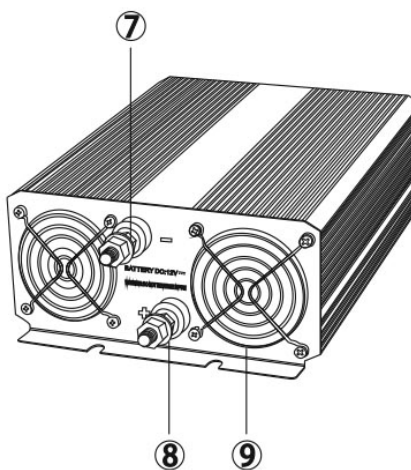

- 7 – 12V negative terminal
- 8 – 12V positive terminal
- 9 – fan

