

Flat suction cup (round)

SUF 25 NBR-ESD-55 SC040

Part no.:10.01.01.14038

<https://www.schmalz.com/10.01.01.14038>

Home > Vacuum Technology for Automation > Vacuum Components > Vacuum Suction Cups > Flat Suction Cups (Round) > SUF 25 NBR-ESD-55 SC040

Flat suction cup (round) f. process- safe handling of smooth or slightly rough surfaces




Size: 25

Suction cup material: Nitrile rubber NBR-ESD

Material hardness [Shore A]: 55 Shore A

Design Data

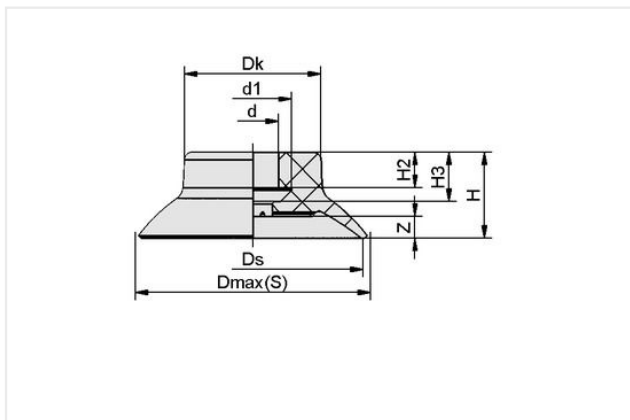

Attribute	Value
d1	10.50 mm
d	7 mm
Dk	15.50 mm
Dmax(S)	28.20 mm
Ds	25 mm
H	11.20 mm
H2	4.80 mm
H3	6.70 mm
Z (Stroke)	2.50 mm

Technical Data

Attribute	Value
Suction force (-600mbar)	23 N
Pull-off force	23 N
Volume	0.90 cm ³
Curve radius (min) (convex)	25 mm
Size	25
Nipple family	SC040
Suction cup material	Nitrile rubber NBR-ESD
Material hardness [Shore A]	55 Shore A

Contact Schmalz

Schmalz Sp.z.o.o. | ul. Fabianowska 131/A1, 62-052 Komorniki, Poland | +48 61 628 67 70 | schmalz@schmalz.pl

Flat suction cup (round)

SUF 25 NBR-ESD-55 SC040

Part no.:10.01.01.14038

<https://www.schmalz.com/10.01.01.14038>

Weight	2.50 g
Product family	SUF

Accessories



SC 040 G1/8-AG

Part no.:10.01.06.02490

Connection geometry: 040

Connection: G1/8"-M

Length L1: 20.2 mm

Fitting length: 6 mm

Nominal diameter dn: 4.1 mm



SC 040 G1/8-IG

Part no.:10.01.06.02482

Connection geometry: 040

Connection: G1/8"-F

Length L1: 20.7 mm

Fitting length: 14 mm

Nominal diameter dn: 4.1 mm

Contact Schmalz

Schmalz Sp.z.o.o. | ul. Fabianowska 131/A1, 62-052 Komorniki, Poland | +48 61 628 67 70 | schmalz@schmalz.pl