

Flat suction pad (round)

SFF 30 EPDM-45 G1/4-AG

Part no.:10.01.01.14268

<https://www.schmalz.com/10.01.01.14268>

Home > Vacuum Technology for Automation > Vacuum Components > Vacuum Suction Cups > Suction Cups for Plastic Films and Paper > Suction Cups SFF / SFB1 > SFF 30 EPDM-45 G1/4-AG

Flat suction cup (round) for dynamic handling of thin and flexible workpieces




Size: 30

Suction cup material: EPDM

Material hardness [Shore A]: 45 Shore A

Design Data

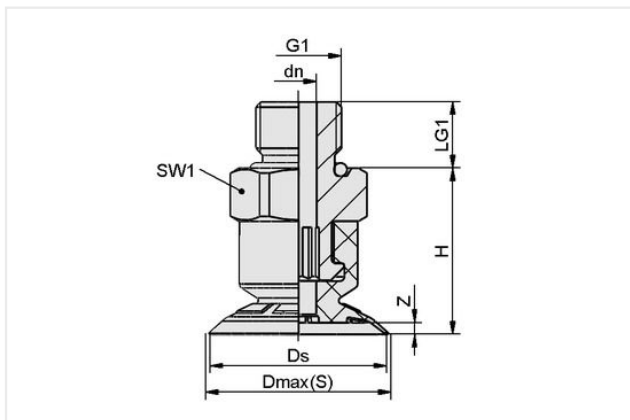

Attribute	Value
Dmax(S)	31.50 mm
Ds	30 mm
dn	4 mm
G1	G1/4-AG
LG1	10 mm
H	19.50 mm
SW1	17 mm
Z (Stroke)	2 mm

Technical Data

Attribute	Value
Suction force (-600mbar)	26.90 N
Volume	1.70 cm ³
Size	30
Number of folds	0
Suction cup material	EPDM
Material hardness [Shore A]	45 Shore A
Weight	9.80 g
Product family	SFF

Contact Schmalz

Schmalz Sp.z.o.o. | ul. Fabianowska 131/A1, 62-052 Komorniki, Poland | +48 61 628 67 70 | schmalz@schmalz.pl

Flat suction pad (round)

SFF 30 EPDM-45 G1/4-AG

Part no.:10.01.01.14268

<https://www.schmalz.com/10.01.01.14268>

Spare parts



SFF 30 EPDM-45 SC040

Part no.:10.01.01.14048

Size: 30

Suction cup material: EPDM

Material hardness [Shore A]: 45 Shore A

Number of folds: 0



SC 040 G1/4-AG

Part no.:10.01.06.03414

Connection geometry: 040

Vacuum connection: G1/4"-M

Fitting length: 6 mm

Nominal diameter dn: 4.1 mm

Contact Schmalz

Schmalz Sp.z.o.o. | ul. Fabianowska 131/A1, 62-052 Komorniki, Poland | +48 61 628 67 70 | schmalz@schmalz.pl