

Precision Screwdriver & Set

91230



- Screwdriver handle for interchangeable blades 2431, 2433
- Handle material - polypropylene (PP)



KT NO.	mm		
91230	100	12	10 / 100

2431



- Combination type
- Phillips / Slotted head, hexagonal shank
- Blade material - SNCM - V alloy steel
- Finishing - chrome plated with black tip



KT NO.	No.	mm	mm	mm	mm		
24312020	PH00	2.0	0.30	4	120	11	20 / 200
24311030	PH0	3.0	0.50	4	120	11	20 / 200
24311140	PH1	4.0	0.60	4	120	11	20 / 200


2433



- Combination type
- Torx head, hexagonal shank
- Blade material - SNCM - V alloy steel
- Finishing - chrome plated with black tip



KT NO.	Size	mm	mm		
24330610	T6 x T10	4	120	11	20 / 200
24330715	T7 x T15	4	120	11	20 / 200
24330820	T8 x T20	4	120	11	20 / 200
24330915	T9 x T15	4	120	11	20 / 200

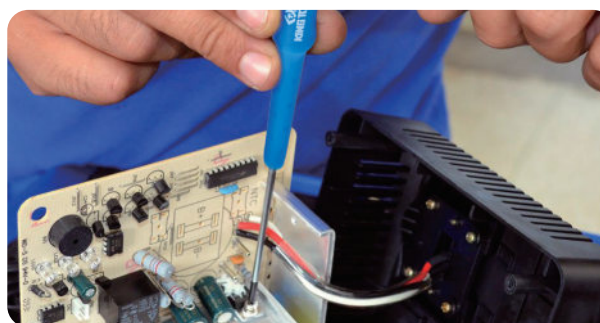

KT NO.	PC.	Contents		
32218MR	8	1.0 x 75, 1.5 x 75, 1.8 x 75, 2.0 x 75, 2.5 x 75, 3.0 x 75, 3.5 x 75, 4.0 x 75 1432	0.32	1 / 30
32209MR	9	0.8 x 40, 1.0 x 40, 1.5 x 40, 1.8 x 40, 2.0 x 40, 2.5 x 40, 3.0 x 40, 3.5 x 40, 4.0 x 40 1432	0.26	1 / 30
32108MR	8	PH000 x 40, PH00 x 40, PH0 x 40, PH1 x 40 1431	0.29	1 / 30
		1.5 x 40, 2.0 x 40, 2.5 x 40, 3.0 x 40 1432		
32118MR	8	PH000 x 75, PH.00 x 75, PH0 x 75, PH1 x 75 1431	0.36	1 / 30
		1.5 x 75, 2.0 x 75, 2.5 x 75, 3.0 x 75 1432		
32308PR	8	T5 x 40, T6 x 40, T7 x 40, T8 x 40, T9 x 50, T10 x 50, T15 x 50, T20 x 50 1433	0.32	1 / 30
32309PR	9	T4 x 40, T5 x 40, T6 x 40, T7 x 40, T8 x 40, T9 x 50, T10 x 50, T15 x 50, T20 x 50 1433	0.26	1 / 30
32607MR	8	91230	0.22	1 / 30
		PH00 x 2.0, PH0 x 3.0, PH1 x 4.0 2431		
		T6 x T10, T7 x T15, T8 x T20, T9 x T15 2433		

