

Double Sides Self-Adjusting Wrench

3616-10

- Self-locking function grip, ideal for fastener 8~32mm
- Anti-slip teeth effective on worn screws
- Slim jaw allows for working in confined area
- Multi-purpose to all shape of fastener

- Spline 12 points
- Square
- Torx
- Hexagon
- 70% Rounded bolt

KT NO.	Capacity mm		
3616-10	8~17 14~32	466	6 / 36




Adjustable Hook Wrench

3641

- The joint is equipped with a spring washer to ensure smooth and reliable operation
- Chrome vanadium alloy steel

KT NO.	Capacity mm	L		
3641-35	13-35	174	104	12 / 144
3641-50	35-50	212	170	12 / 108
3641-80	50-80	285	395	10 / 60
3641-C0	80-120	348	689	5 / 30
3641-I0	120-180	480	1554	4 / 16

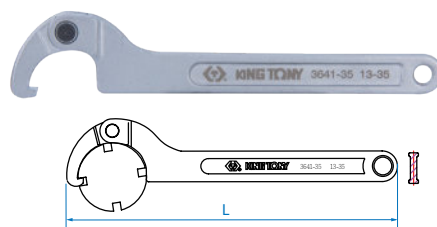

Chain Wrench

3204

- Chain wrench for oil filter



KT NO.	Overall length Inch mm	Capacity(M) mm		
3204	8-3/4 225	Ø 60~140	411	50

Strap Wrench

3203

- Strap wrench for oil filter



KT NO.	Overall length Inch mm	Capacity(M) mm		
3203	8-3/4 223	Ø 60~140	276	50
320300		Strap	46	80
3203A0	8-3/4 223	Ø 60~260	300	45
320301		Strap	73	80

320670

- Aluminum alloy handle and strong polyester strap for tight grip
- Suitable for oil filter or any polished pipe



KT NO.	Overall Length Inch mm	Capacity mm		
320670	12 295	Ø 60~180	344	25 / 50
320600		Polyester strap	35	25 / 50

