

Impact Bit Socket

KT No. & D1



3065M

3/8"

- For hexagon head screw
- DIN 3121



KT NO.	mm	L mm	Max. torq N·m	g	g
306504M	H4	90	20.8	39	8 / 160
306505M	H5	90	36.0	44	8 / 160
306506M	H6	90	62.4	50	8 / 160
306508M	H8	90	144.0	66	8 / 160
306510M	H10	90	264.0	86	8 / 160

3053

3063

3/8"

- For torx internal screw
- DIN 3121



KT NO.	Size	L mm	g	g
305310	T10	55	35	12 / 360
305315	T15	55	34	12 / 360
305320	T20	55	35	12 / 360
305325	T25	55	36	12 / 360
305327	T27	55	36	12 / 360
305330	T30	55	36	12 / 360
305340	T40	55	39	12 / 360
305345	T45	55	43	12 / 360
305350	T50	55	44	12 / 360
305355	T55	55	52	12 / 288
305360	T60	55	60	12 / 288
306320	T20	90	42	8 / 160
306325	T25	90	42	8 / 160
306327	T27	90	43	8 / 160
306330	T30	90	45	8 / 160
306340	T40	90	50	8 / 160
306345	T45	90	57	8 / 160
306350	T50	90	64	8 / 160
306355	T55	90	82	8 / 160

Impact Accessory

3862P

3/8"

- Adapter
- Convert to 1/4" drive
- 3862P → Max. torque : 62 N·m
- DIN 3121



KT NO.	Spec.	D mm	g	g
3862P	3/8" F x 1/4" M	20.8	32	24 / 384

3864P

3/8"

- Adapter
- Convert to 1/2" drive
- DIN 3121



KT NO.	Spec.	D mm	g	g
3864P	3/8" F x 1/2" M	20.8	53	24 / 384

3147

3/8"

- Bit holder



KT NO.	Size	L mm	g	g
314708S	1/4"	40	41	12 / 420
314710S	5/16"	40	43	12 / 420
314710M	10mm	40	42	12 / 420

3260P

3/8"

- Extension bar
- DIN 3121




KT NO.	Overall length inch	mm	g	g
3260-03P	3	75	98	6 / 120
3260-04P	4	100	121	8 / 160
3260-05P	5	125	147	8 / 144
3260-06P	6	150	169	5 / 100
3260-08P	8	200	217	6 / 72
3260-10P	10	250	264	6 / 54

3796P

3/8"

- Universal joint
- DIN 3121

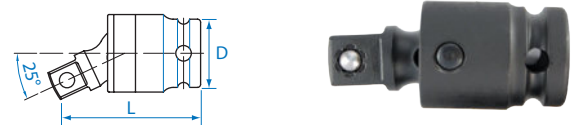

KT NO.	Overall length inch	mm	D mm	g	g
3796P	2	50	22	87	10 / 200

90608

90609

3/8"

- Locking pin
- Chrome vanadium steel
- DIN 3129



KT NO. Desp. Ø d / ℓ Applied to socket sizes

90608	pin	2.5	14	3535M (6~12 mm) 3535S (1/4~1/2 inch) 3435M (6~12 mm) 3435S (1/4~1/2 inch) 3055M (4~12 mm) 3055S (3/16~1/2 inch) 3065M (4~10 mm) 3053 (T10~T15) 3575M (E5~E14) 3053.3055.3065.3147.3862.3864
-------	-----	-----	----	--

90609	pin	2.5	16	3535M (13~19 mm) 3535S (9/16~3/4 inch) 3435M (13~24 mm) 3435S (9/16~7/8 inch) 3260.3796
-------	-----	-----	----	---