

Spark Plug Socket

KT No. & D1



3630		3660		3635		3665	
3670		3675					

- 6 / 12 points
- Size combined- 16.0mm (5/8") - 20.8mm (13/16")
- Inside sleeve - rubber / magnet
- DIN 3120



KT NO.	Type	Size inch mm	D mm	L mm		
363016	12 points Rubber	5/8 16.0	21	70	85	10 / 200
363021	12 points Rubber	13/16 20.8	27.7	70	149	12 / 120
366021	12 points Magnet	13/16 20.8	27.7	70	149	12 / 120
363516	6 points Rubber	5/8 16.0	21	70	88	10 / 200
366516	6 points Magnet	5/8 16.0	21	70	89	10 / 200
363521	6 points Rubber	13/16 20.8	27.7	70	153	12 / 120
366521	6 points Magnet	13/16 20.8	27.7	70	155	12 / 120
367018	12 points Metal clip	- 18.0	23.8	63	84	12 / 120
367021	12 points Metal clip	13/16 20.8	27.7	70	167	12 / 120
367516	6 points Metal clip	5/8 16.0	21.0	70	86	10 / 200
367518	6 points Metal clip	- 18.0	23.8	63	91	12 / 120
367521	6 points Metal clip	13/16 20.8	27.7	70	169	12 / 120



363016



363021



366021



363516




366516




363521



366521

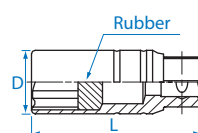

Rubber

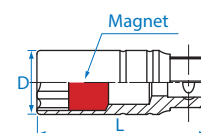


Magnet



367516



 367018



Metal clip

Glow Plug Socket & Set

3785M

- The socket has a Sprung-loaded clip with ball bearing end to stop the glow plug from falling out
- Suitable for the removal of glow plugs in most diesel engines




KT NO.	mm	D1 mm	D2 mm	L mm		
378508M	8	13.5	17.8	120	131	10 / 100
378509M	9	13.5	17.8	127	120	10 / 100
378510M	10	13.5	17.8	128	123	10 / 100
378512M	12	17.8	17.8	136	147	10 / 100
378514M	14	17.8	17.8	142	139	10 / 100
378516M	16	19.8	17.8	157	154	10 / 100

3716MR

Blow case size (mm):
260 x 160 x 64 (0.094 cuft)

6
PC.

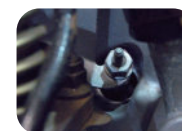

Contents

1.23

1 / 10

3785M 8, 9, 10, 12, 14, 16