

Accessory



The offset extension bar has less strength than normal extension bar. Do not use as a normal extension bar.

4121 1/2"

- Adjustable handle
- Push-Lock design



KT NO.	Overall length inch	mm		
4121-11GR	11-1/2	295	535	1 / 20

4251 1/2"

- Extension bar
- DIN 3123



KT NO.	Overall length inch	mm		
4251-02R	2	55	105	12 / 216
4251-03R	3	75	143	6 / 120
4251-04R	4	100	182	4 / 80
4251-05R	5	125	197	4 / 80
4251-06R	6	150	231	4 / 64
4251-08R	8	200	294	4 / 80
4251-10R	10	250	364	4 / 64

4104PR 1/2"

- Extension bar



4 PC.

Contents



0.84



1 / 25

	4251	3"	5"	6"	10"
--	------	----	----	----	-----

4221 1/2"

- Extension bar
- DIN 3123



KT NO.	Overall length inch	mm		
4221-18	18	450	548	1 / 20
4221-24	24	600	685	1 / 20
4221-30	30	750	860	1 / 20
4221-36	36	900	1055	1 / 20

4223 1/2"

- Offset extension bar
- Max. torque : 320 N·m
- DIN 3123



KT NO.	Overall length inch	mm		
4223-02R	2	55	98	12 / 216
4223-05R	5	125	194	4 / 80
4223-10R	10	250	358	4 / 64

4293 1/2"


- Multi-function of extension bar and offset extension bar
- Max. torque : 320 N·m
- DIN 3123



KT NO.	Overall length inch	mm		
4293-02	2	55	97	12 / 216
4293-05	5	125	191	4 / 80
4293-10	10	250	356	4 / 64

4311 1/2"

- Speed brace
- DIN 3122

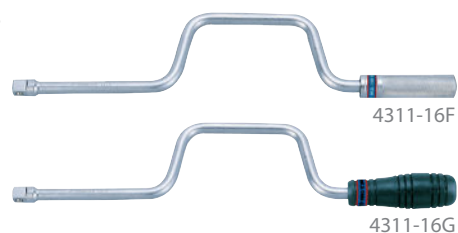

4311-16F

4311-16G

KT NO.	Overall length inch	mm		
4311-16F	16-1/4	412	610	5 / 40
4311-16G	16-1/4	412	499	5 / 40

4452 1/2"

- Flexible handle
- Action degree -180°
- DIN 3122



4452DK

KT NO.	Overall length inch	mm		
4452-15FR	15	375	718	2 / 24
4452-18FR	18	450	810	2 / 20
4452DK	renewal kits(for 15F/18F)		62	-

KT NO.	Overall length inch	mm		
4452-24FR	24	600	1138	20
4452DK1	renewal kits(for 24F)		62	-

4453 1/2"

- Flexible handle
- Action degree -180°
- New pattern design added in firm and powerful elements
- New forge technologies I-Beam shank offer 15% lightweight
- DIN 3122



4452DK

4453-15F					4453-15F
4453-18F					4453-18F
KT NO.	Overall length inch	mm			
4453-15F	15	375	630	2 / 24	
4453-18F	18	450	708	2 / 20	
4452DK	renewal kits(for 15F/18F)		62	-	