


T-type Universal Standard Socket Wrench

5722M


- T-type 25° universal standard socket wrench

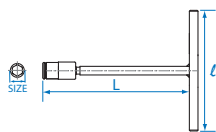

KT NO.	Size mm	l mm	L mm	g	Box / Carton
572210M	10	150	170	400	10 / 60
572212M	12	150	170	400	10 / 60

5742M

 
- T-type 25° universal standard socket wrench



KT NO.	Size mm	l mm	L mm	g	Box / Carton
574208M	8	200	320	328	10 / 40
574212M	12	200	320	332	10 / 40
574213M	13	200	320	333	10 / 40
574214M	14	200	320	335	10 / 40

5752M

 
- T-type 25° universal standard socket wrench



KT NO.	Size mm	l mm	L mm	g	Box / Carton
575208M	8	200	450	427	10 / 40
575210M	10	200	450	430	10 / 40
575212M	12	200	450	432	10 / 40
575213M	13	200	450	433	10 / 40
575214M	14	200	450	435	10 / 40
575217M	17	200	450	440	10 / 40

5762M

 
- T-type 25° universal standard socket wrench



KT NO.	Size mm	l mm	L mm	g	Box / Carton
576208M	8	200	600	519	10 / 40
576210M	10	200	600	520	10 / 40
576213M	13	200	600	523	10 / 40
576214M	14	200	600	525	10 / 40
576217M	17	200	600	540	10 / 40

5774M

- T-type 90° universal standard socket wrench
- 2 PC. sliding handle for easy storage

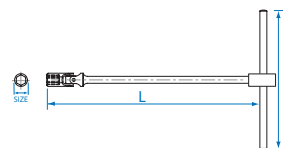

KT NO.	Size mm	l mm	L mm	g	Box / Carton
577406M	6	200	390	420	10 / 30
577407M	7	200	390	420	10 / 30
577408M	8	200	390	420	10 / 30
577409M	9	200	390	420	10 / 30
577410M	10	200	500	480	10 / 30
577411M	11	200	500	480	10 / 30
577412M	12	200	500	480	10 / 30
577413M	13	200	500	480	10 / 30
577414M	14	200	500	500	10 / 30
577415M	15	200	500	500	10 / 30
577416M	16	200	500	500	10 / 30
577417M	17	200	500	500	10 / 30
577418M	18	200	500	500	10 / 30
577419M	19	200	500	500	10 / 30